
1. INTRODUCTION



This manual describes how this scale works and how to get the most out of it in terms of performance.

FG series platform scales have the following features:

- ✂ The FG series has three kinds of weight display resolution, 1/3,000, 1/6,000 (1/7,500) and 1/12,000 (1/15,000).
- ✂ There are 2 sizes of weighing pan. The FG-KAL has a larger pan and the FG-KAM/KBM has a smaller pan. The FG-KAL/KAM has a display column and the FG-KBM is a without column model. You can select a model that suits your own application.
- ✂ As power source, you can use an AC adapter or C size dry batteries.
- ✂ The counting function easily counts the number of articles of the same weight.
- ✂ The comparator function compares the display value with upper limit and lower limit. The display shows the result and the optional FG-24 can output it as a relay signal.
- ✂ The optional FG-23 and FG-24 has an RS-232C interface and can output the weighing data to connect with a printer, computer and so on.

2. UNPACKING

When unpacking, check whether all of the following items are included:

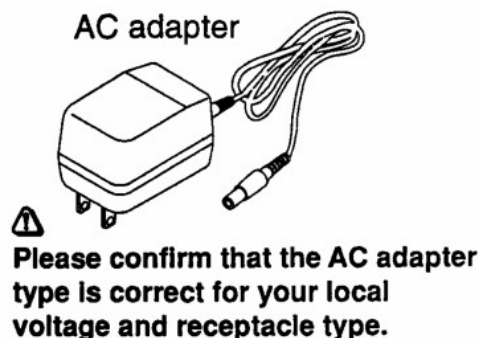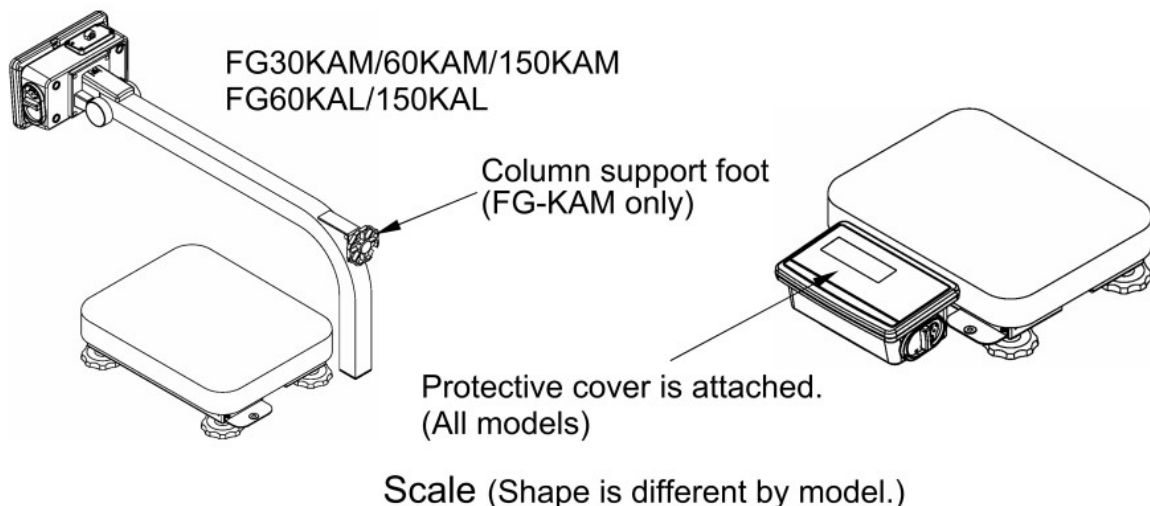

Instruction manual

