


A10338 Steel vertical band for SP pipe

Hinged vertical band for spiral duct

Part number A10338 Steel vertical band for SP pipe

Units (mm)

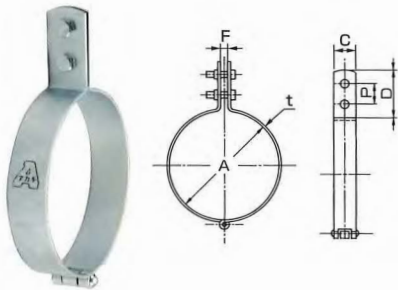


Size code	Size	Applicable pipe outer diameter	t	C	Tightening bolt Dia. x Length	D	P	F
0012	φ100	103	3.2	25	M6 × 20	45	20	6
0027	φ125	128	3.2	25	M6 × 20	45	20	6
0031	φ150	153	3.2	25	M6 × 20	45	20	6
0046	φ200	203	3.2	25	M6 × 20	45	20	6
0065	φ225	228	3.2	25	M6 × 20	45	20	6
0070	φ250	253	3.2	25	M6 × 20	45	20	6
0084	φ300	303	3.2	25	M6 × 20	45	20	6

A10355 Stainless steel band for rain gutter

Lantern type vertical band for rain gutter

Part number A10355 Stainless steel band for rain gutter

Units (mm)

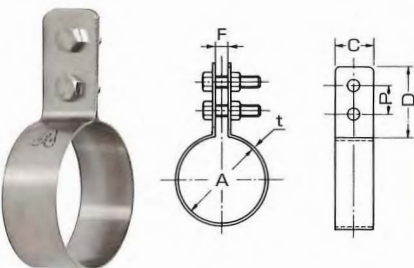


Size code	Size	Applicable pipe outer diameter	t	C	Tightening bolt Dia. x Length	D	P	F
0013	50	60	1.0	25	M6 × 20	45	20	6
0028	65	76	1.0	25	M6 × 20	45	20	6
0032	75	89	1.0	25	M6 × 20	45	20	6
0047	100	114	1.0	25	M6 × 20	45	20	6

A10357 Stainless steel assembled band for rain gutter

Assembled vertical band for rain gutter

Part number A10357 Stainless steel assembled band for rain gutter

Units (mm)

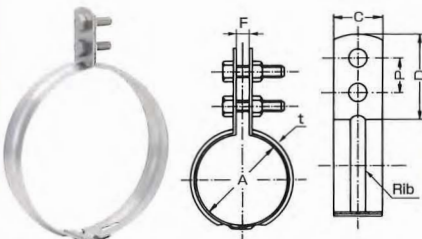

Size code	Size	Applicable pipe outer diameter	t	C	Tightening bolt Dia. x Length	D	P	F
0018	125	140	1.5	32	M8 × 25	45	20	8
0022	150	165	1.5	32	M8 × 25	45	20	8

A23049 Vertical band for polyethylene pipe Confirm delivery

A23056 Stainless steel vertical band for polyethylene pipe Confirm delivery

Vertical band for mains water polyethylene pipe

Part number A23049 Vertical band for polyethylene pipe

A23056 Stainless steel vertical band for polyethylene pipe

Units (mm)



A23049

A23056

Diameter size (A)	Applicable pipe outer diameter	Size code	
		A23049	A23056
		Steel	SUS304
20A	27	0017	0011
25A	32	0021	0026
30A	40	0036	0045
40A	50	0055	0050
50A	63	0060	0064
75A	90	0074	0079
100A	125	0089	0083
150A	180	0093	0098
200A	250	0106	0115