


**A10342** Anti-vibration vertical band with 3 t rubber for CL pipe Confirm delivery

Anti-vibration supplementary vertical band for outer surface coated steel pipe / With 3 mm rubber

Part number A10342 Anti-vibration vertical band with 3 t rubber for CL pipe Units (mm)

Size code	Diameter size (A)	Nominal diameter (B)	Applicable pipe outer diameter	t	C	Tightening bolt Dia. x Length	D	P	F
0015	15A	1/2	25.7	2.0	25	M 6 x 20	45	20	6
0020	20A	3/4	31.2	2.0	25	M 6 x 20	45	20	6
0034	25A	1	37.6	2.0	25	M 6 x 20	45	20	6
0049	32A	1 1/4	46.3	2.0	25	M 6 x 20	45	20	6
0053	40A	1 1/2	52.2	2.0	25	M 6 x 20	45	20	6
0068	50A	2	64.1	2.0	25	M 6 x 20	45	20	6
0072	65A	2 1/2	79.9	2.0	25	M 6 x 20	45	20	6
0087	80A	3	92.7	2.0	25	M 6 x 20	45	20	6
0091	100A	4	118.3	2.0	25	M 6 x 20	45	20	6
0104	125A	5	143.8	3.2	32	M10 x 30	55	27	8
0119	150A	6	170.2	3.2	32	M10 x 30	55	27	8

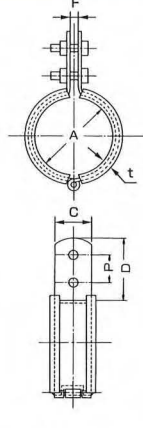


**A10360** Stainless steel anti-vibration vertical band with 3 t rubber for CL pipe Confirm delivery

Anti-vibration supplementary vertical band for outer surface coated steel pipe / With 3 mm rubber

Part number A10360 Stainless steel anti-vibration vertical band with 3 t rubber for CL pipe Units (mm)

Size code	Diameter size (A)	Nominal diameter (B)	Applicable pipe outer diameter	t	C	Tightening bolt Dia. x Length	D	P	F
0013	15A	1/2	25.7	2.0	25	M 6 x 20	45	20	6
0028	20A	3/4	31.2	2.0	25	M 6 x 20	45	20	6
0032	25A	1	37.6	2.0	25	M 6 x 20	45	20	6
0047	32A	1 1/4	46.3	2.0	25	M 6 x 20	45	20	6
0051	40A	1 1/2	52.2	2.0	25	M 6 x 20	45	20	6
0066	50A	2	64.1	2.0	25	M 6 x 20	45	20	6
0085	65A	2 1/2	79.9	2.0	25	M 6 x 20	45	20	6
0090	80A	3	92.7	2.0	25	M 6 x 20	45	20	6
0102	100A	4	118.3	2.0	25	M 6 x 20	45	20	6
0117	125A	5	143.8	3.0	25	M10 x 35	56	27	8
0121	150A	6	170.2	3.0	25	M10 x 35	56	27	8

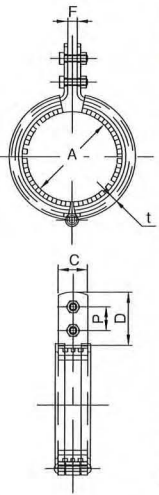

A10343

**A10343** Anti-vibration vertical band with 10 t rubber for CL pipe Confirm delivery

**A10362** Stainless steel anti-vibration vertical band with 10 t rubber for CL pipe Confirm delivery

Anti-vibration supplementary vertical band for outer surface coated steel pipe / With 10 mm rubber

Part number A10343 Anti-vibration vertical band with 10 t rubber for CL pipe Units (mm)

Size code	Diameter size (A)	Nominal diameter (B)	Applicable pipe outer diameter	t	C	Tightening bolt Dia. x Length	D	P	F
0012	15A	1/2	25.7	2.0	25	M 6 x 20	45	20	6
0027	20A	3/4	31.2	2.0	25	M 6 x 20	45	20	6
0031	25A	1	37.6	2.0	25	M 6 x 20	45	20	6
0046	32A	1 1/4	46.3	2.0	25	M 6 x 20	45	20	6
0065	40A	1 1/2	52.2	2.0	25	M 6 x 20	45	20	6
0070	50A	2	64.1	2.0	25	M 6 x 20	45	20	6
0084	65A	2 1/2	79.9	2.0	25	M 6 x 20	45	20	6
0099	80A	3	92.7	2.0	25	M 6 x 20	45	20	6
0101	100A	4	118.3	2.0	25	M 6 x 20	45	20	6
0116	125A	5	143.8	3.2	32	M10 x 30	55	27	8
0135	150A	6	170.2	3.2	32	M10 x 30	55	27	8



A10362

Part number A10362 Stainless steel anti-vibration vertical band with 10 t rubber for CL pipe Units (mm)

Size code	Diameter size (A)	Nominal diameter (B)	Applicable pipe outer diameter	t	C	Tightening bolt Dia. x Length	D	P	F
0018	15A	1/2	25.7	2.0	25	M 6 x 20	45	20	6
0022	20A	3/4	31.2	2.0	25	M 6 x 20	45	20	6
0037	25A	1	37.6	2.0	25	M 6 x 20	45	20	6
0041	32A	1 1/4	46.3	2.0	25	M 6 x 20	45	20	6
0056	40A	1 1/2	52.2	2.0	25	M 6 x 20	45	20	6
0075	50A	2	64.1	2.0	25	M 6 x 20	45	20	6
0080	65A	2 1/2	79.9	2.0	25	M 6 x 20	45	20	6
0094	80A	3	92.7	2.0	25	M 6 x 20	45	20	6
0107	100A	4	118.3	2.0	25	M 6 x 20	45	20	6
0111	125A	5	143.8	3.0	32	M10 x 35	55	27	8
0126	150A	6	170.2	3.0	32	M10 x 35	55	27	8

The shape of the rubber may change for larger diameters.

