


A10367 T-bracket

Mounting bracket for vertical bands / Pressed metal sheet type

Part number A10367

T-bracket (25 wide) Units (mm)

Size code	H
0014	50
0029	60
0033	70
0048	80
0052	100
0067	120
0071	150
0086	200

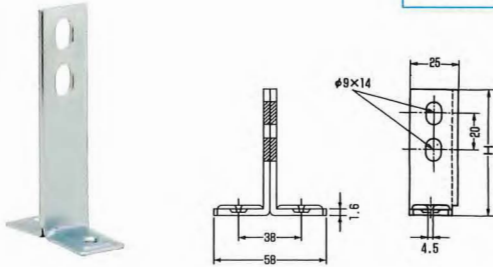

A11214 Dip-plated T-bracket


Mounting bracket for vertical bands / Pressed metal sheet type

Part number A11214

Dip-plated T-bracket (25 wide)

Units (mm)

Size code	H
0024	50
0039	60
0010	70
0043	80
0058	100
0062	120
0077	150
0081	200

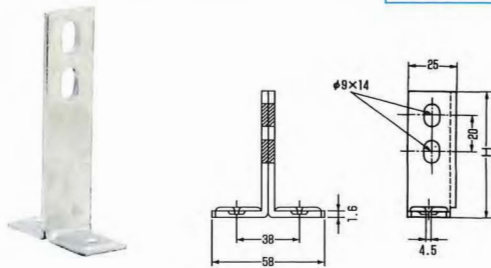

A10368 Single-hole T-bracket

Mounting bracket for vertical bands / Pressed metal sheet type

Part number A10368

Single-hole T-bracket (25 wide)

Units (mm)

Size code	H	L	P	D
0011	30	58	38	$\phi 9 \times 14$
0026	40	58	38	$\phi 9 \times 14$
0045	50	58	38	$\phi 9 \times 34$
0050	60	58	38	$\phi 9 \times 34$
0064	70	58	38	$\phi 9 \times 34$
0079	80	58	38	$\phi 9 \times 34$
0083	100	58	38	$\phi 9 \times 34$
0098	120	58	38	$\phi 9 \times 34$
0115	150	58	38	$\phi 9 \times 34$
0120	200	58	38	$\phi 9 \times 34$

Single-hole T-bracket (32 wide)

Units (mm)

Size code	H	L	P	D
0134	60	65	40	$\phi 11 \times 40$
0149	80	65	40	$\phi 11 \times 40$
0153	100	65	40	$\phi 11 \times 40$
0168	120	65	40	$\phi 11 \times 40$
0172	150	65	40	$\phi 11 \times 40$
0187	200	65	40	$\phi 11 \times 40$

