 

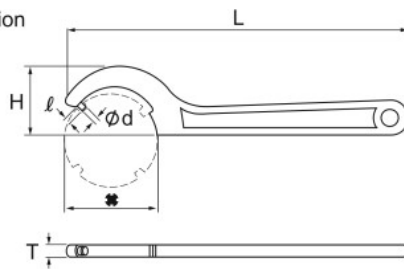


FP Hook Spanner, Pin Type


Code	 mm	d mm	ℓ mm	T mm	H mm	L mm	Weight g		Price ¥
FP2528	25~28	2.5	2	5	21	136	50	10	1,580
FP3032	30~32	2.5	2	5	21	136	50	10	1,580
FP3438	34~38	3.5	3.5	6	28	160	100	10	1,660
FP4042	40~42	3.5	3.5	6	30	173	100	10	1,800
FP4548	45~48	4.5	4	6.5	34	195	150	10	2,060
FP5255	50~55	4.5	4	6.5	40	208	150	10	2,190
FP5865	58~65	4.5	5	7.5	46	230	220	10	2,400
FP6570	65~70	4.5	5	7.5	46	230	220	10	2,560
FP7075	70~75	5.5	5	8	52	246	275	10	2,560
FP8085	80~85	5.5	6	8.5	62	270	390	10	3,200
NEW FP8592	85~92	5.5	6	8.5	62	270	390	10	3,310
FP9298	92~100	6	6	8.5	68	286	400	10	3,430
FPP105	105~115	6	6	10	82	333	710	5	5,410



• Cathodic Electrodeposition



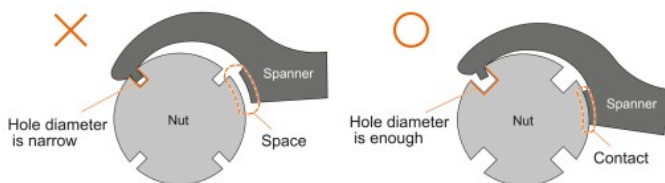Do not attach the spanner into the narrow groove as it may damage the spanner.



TOOL SETS

SPANNERS

STRIKING FACE WRENCHES

HOOK SPANNERS

DX2000 TOOLS
HEXAGON KEY WRENCHES

HEXAGON KEY WRENCHES

TORQUE WRENCHES

CROWFOOT WRENCHES

SOCKETS

OTHER TOOLS