


T-Handled Separate type / Metric


Code	○ mm	L ₁ mm	D ₁ mm	L ₂ mm	D ₂ mm	L ₃ mm	Weight g		Price ¥
VTH0300	3	125	9	120	6.4	210	35	10	3,180
VTH0400	4	180	11	120	8.4	220	69	10	3,500
VTH0500	5	180	11	120	8.4	220	70	10	3,650
VTH0600	6	210	16	140	10.4	245	135	5	3,990
VTH0800	8	250	19	175	11.6	280	200	5	4,590

• Nickel Chrome Plating

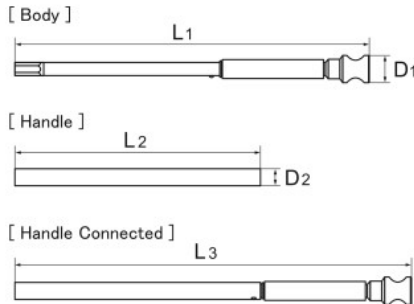


The handle can be stored in the body, so it takes up less storage space than existing T-shaped hexagon key wrenches, making it convenient to carry around.
The quick-turn collar enables speedy work.
The handle slides for use in either T or L configuration, depending on work requirements.

Plastic Handle type / Metric

Code	○ mm	L mm	ℓ mm	W mm	Weight g		Price ¥
ATL0250	2.5	152	127	75	20	10	690
ATL0300	3	170	145	75	22	10	760
ATL0400	4	182	152	90	40	10	840
ATL0500	5	206	176	90	60	10	970
ATL0600	6	228	198	90	75	10	1,100

• Nickel Chrome Plating
• Plastic Handle

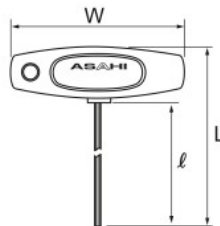

TOOL SETS
SPANNERS
STRIKING FACE WRENCHES
HOOK SPANNERS
DX2000 TOOLS
HEXAGON KEY WRENCHES
HEXAGON KEY WRENCHES
TORQUE WRENCHES
CROWFOOT WRENCHES
SOCKETS
OTHER TOOLS