


コーナーRカッター (2枚刃)

2-Flute Corner Radius Cutter

ACR

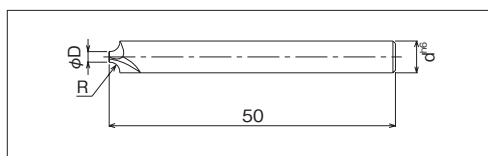

※刃部詳細図はP.166参照

■ 精密加工用高精度インナー Rカッターです。
High precision inner radius cutter for fine processing

R公差：±0.02
R Tolerance



単位 Unit : mm

| 型番 CODE NUMBER | R | 先端径 φD | 全長 L | シャンク d | 定価 ¥ |
|-------------------|------|-----------|---------|-----------|---------|
| ACR-2010 | 0.1 | 1 | 50 | 3 | 13,500 |
| ACR-2015 | 0.15 | 1 | 50 | 3 | 13,500 |
| ACR-2020 | 0.2 | 1 | 50 | 3 | 11,700 |
| ACR-2025 | 0.25 | 1 | 50 | 3 | 11,700 |
| ACR-2030 | 0.3 | 1 | 50 | 3 | 11,700 |
| ACR-2035 | 0.35 | 1 | 50 | 3 | 11,700 |
| ACR-2040 | 0.4 | 1 | 50 | 3 | 10,000 |
| ACR-2045 | 0.45 | 1 | 50 | 3 | 10,000 |
| ACR-2050 | 0.5 | 1 | 50 | 3 | 7,300 |
| ACR-2055 | 0.55 | 1 | 50 | 3 | 8,200 |
| ACR-2060 | 0.6 | 1.5 | 50 | 4 | 8,200 |
| ACR-2065 | 0.65 | 1.5 | 50 | 4 | 8,200 |
| ACR-2070 | 0.7 | 1.5 | 50 | 4 | 8,200 |
| ACR-2075 | 0.75 | 1.5 | 50 | 4 | 7,300 |
| ACR-2080 | 0.8 | 1.5 | 50 | 4 | 8,200 |
| ACR-2085 | 0.85 | 1.5 | 50 | 4 | 8,200 |
| ACR-2090 | 0.9 | 1.5 | 50 | 4 | 8,200 |
| ACR-2095 | 0.95 | 1.5 | 50 | 4 | 8,200 |
| ACR-2100 | 1 | 1.5 | 50 | 4 | 7,300 |
| ACR-2105 | 1.05 | 1.5 | 50 | 4 | 8,200 |
| ACR-2110 | 1.1 | 2 | 50 | 6 | 8,200 |
| ACR-2115 | 1.15 | 2 | 50 | 6 | 8,200 |
| ACR-2120 | 1.2 | 2 | 50 | 6 | 8,200 |
| ACR-2125 | 1.25 | 2 | 50 | 6 | 7,300 |
| ACR-2130 | 1.3 | 2 | 50 | 6 | 12,200 |
| ACR-2135 | 1.35 | 2 | 50 | 6 | 12,200 |
| ACR-2140 | 1.4 | 2 | 50 | 6 | 12,200 |

| 型番 CODE NUMBER | R | 先端径 φD | 全長 L | シャンク d | 定価 ¥ |
|-------------------|------|-----------|---------|-----------|---------|
| ACR-2145 | 1.45 | 2 | 50 | 6 | 12,200 |
| ACR-2150 | 1.5 | 2 | 50 | 6 | 11,200 |
| ACR-2155 | 1.55 | 2 | 50 | 6 | 12,200 |
| ACR-2160 | 1.6 | 2 | 50 | 6 | 12,200 |
| ACR-2165 | 1.65 | 2 | 50 | 6 | 12,200 |
| ACR-2170 | 1.7 | 2 | 50 | 6 | 12,200 |
| ACR-2175 | 1.75 | 2 | 50 | 6 | 11,200 |
| ACR-2180 | 1.8 | 2 | 50 | 6 | 12,200 |
| ACR-2185 | 1.85 | 2.5 | 50 | 8 | 13,700 |
| ACR-2190 | 1.9 | 2.5 | 50 | 8 | 13,700 |
| ACR-2195 | 1.95 | 2.5 | 50 | 8 | 13,700 |
| ACR-2200 | 2 | 2.5 | 50 | 8 | 11,200 |
| ACR-2205 | 2.05 | 2.5 | 50 | 8 | 13,700 |
| ACR-2210 | 2.1 | 2.5 | 50 | 8 | 13,700 |
| ACR-2215 | 2.15 | 2.5 | 50 | 8 | 13,700 |
| ACR-2220 | 2.2 | 2.5 | 50 | 8 | 13,700 |
| ACR-2225 | 2.25 | 2.5 | 50 | 8 | 13,700 |
| ACR-2230 | 2.3 | 2.5 | 50 | 8 | 13,700 |
| ACR-2235 | 2.35 | 2.5 | 50 | 8 | 13,700 |
| ACR-2240 | 2.4 | 2.5 | 50 | 8 | 13,700 |
| ACR-2245 | 2.45 | 2.5 | 50 | 8 | 13,700 |
| ACR-2250 | 2.5 | 2.5 | 50 | 8 | 11,700 |