

LRA-TPA, BRA-TPA, LKRA-TPA, BKRA-TPA series

**Light duty castors with bolt hole,
wheel with thermoplastic
rubber tread**

50–120 kg



Bracket: LRA/BRA, LKRA/BKRA series

- pressed steel, zinc-plated, blue-passivated, Cr6-free

Swivel bracket:


- double ball bearing in the swivel head
- strong central kingpin
- minimum swivel head play and smooth rolling characteristic and increased service life due to the special dynamic Blickle riveting process
- synthetic "stop-fix" brake lever for series LRA, steel brake lever for series LKRA

Wheel: TPA series

- tread: high-quality thermoplastic rubber-elastomer (TPE), hardness 85 Shore A, colour grey, non-marking, oil containing
- wheel centre: high-quality polypropylene, impact resistant, colour silver grey ("ELS" version colour black)

Additional details:

- bracket series: page 86
- brakes: page 112–113
- wheel series: page 122
- bearing types: page 84–85

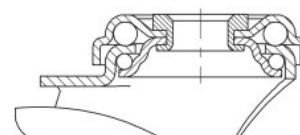

Swivel castors	Fixed castors	Swivel castors with "stop-fix" brake	Wheel Ø [mm]	Wheel width [mm]	Load capacity [kg]	Bearing type	Total height [mm]	Plate Ø [mm]	Bolt hole Ø [mm]	Offset swivel castor [mm]
LRA-TPA 50G	BRA-TPA 50G	LRA-TPA 50G-FI *	50	19	50	plain bore	69	43	11	23
LRA-TPA 50KF	BRA-TPA 50KF	LRA-TPA 50KF-FI *	50	19	50	ball bearing (C)	69	43	11	23
LRA-TPA 75G	BRA-TPA 75G	LRA-TPA 75G-FI *	75	25	75	plain bore	98	43	11	29
LRA-TPA 75KF	BRA-TPA 75KF	LRA-TPA 75KF-FI *	75	25	75	ball bearing (C)	98	43	11	29
LKRA-TPA 80G	BKRA-TPA 80G	LKRA-TPA 80G-FI	80	32	100	plain bore	108	57	13	40
LKRA-TPA 80G-11		LKRA-TPA 80G-11-FI	80	32	100	plain bore	108	57	11	40
LKRA-TPA 80KF	BKRA-TPA 80KF	LKRA-TPA 80KF-FI	80	32	100	ball bearing (C)	108	57	13	40
LKRA-TPA 80KF-11		LKRA-TPA 80KF-11-FI	80	32	100	ball bearing (C)	108	57	11	40
LRA-TPA 100G		LRA-TPA 100G-FI *	100	25	70	plain bore	121	43	11	33
LKRA-TPA 101G	BKRA-TPA 101G	LKRA-TPA 101G-FI	100	32	110	plain bore	133	57	13	40
LKRA-TPA 101G-11		LKRA-TPA 101G-11-FI	100	32	110	plain bore	133	57	11	40
LKRA-TPA 101KF	BKRA-TPA 101KF	LKRA-TPA 101KF-FI	100	32	110	ball bearing (C)	133	57	13	40
LKRA-TPA 101KF-11		LKRA-TPA 101KF-11-FI	100	32	110	ball bearing (C)	133	57	11	40
LKRA-TPA 126G	BKRA-TPA 126G	LKRA-TPA 126G-FI	125	32	120	plain bore	158	57	13	40
LKRA-TPA 126G-11		LKRA-TPA 126G-11-FI	125	32	120	plain bore	158	57	11	40
LKRA-TPA 126KF	BKRA-TPA 126KF	LKRA-TPA 126KF-FI	125	32	120	ball bearing (C)	158	57	13	40
LKRA-TPA 126KF-11		LKRA-TPA 126KF-11-FI	125	32	120	ball bearing (C)	158	57	11	40

* Synthetic brake lever, see image below

For stainless steel versions, see page 390

Versions / options**



	plain bore version	with synthetic brake lever	electrically conductive version, non-marking grey	with threaded pin M10 x 30 M12 x 30	with plug-in pin Ø 11 x 30.5	with synthetic expander fitting	with metal expander fitting
Technical description page			50	104	105	105	105
Product code suffix			-ELS	-GS10 / -GS12	-ES	see page 148	see page 148
Available for		series LRA...-FI as standard	all***	-GS10: series LRA -GS12: series LKRA	series LRA swivel castors****	swivel castors with bolt hole Ø 11 mm (except ELS)	swivel castors with bolt hole Ø 11 mm

** Other versions / options: buffers AG / ARG series see page 148 (page 116 for technical information)

*** Wheel load capacity of electrically conductive version reduced by 35%

**** Synthetic castor socket for round tubes see page 148