


MINI FERRULE

Material 316L

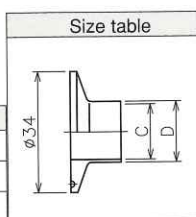

SIZE	D	C
8A	13.8	10.5
10A	17.3	14.0
15A	21.7	17.5




MINI BLIND FERRULE

Material 316L



SIZE	A
8A	34
10A	34
15A	34

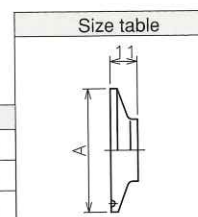


MINI 90° ELBOW

Material 316L



SIZE	D	A
8A	13.8	38
10A	17.3	38
15A	21.7	38

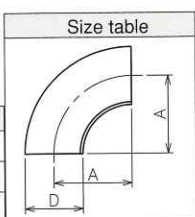


MINI 45° ELBOW

Material 316L



SIZE	D	A
8A	13.8	14.8
10A	17.3	14.8
15A	21.7	14.8

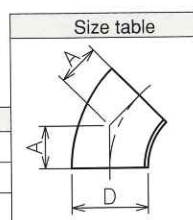


MINI TEE

Material 316L



SIZE	D	A
8A	13.8	38
10A	17.3	38
15A	21.7	38

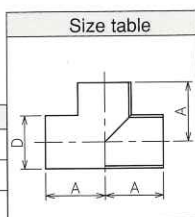


MINI 90° FERRULE ELBOW

Material 316L



SIZE	A
8A	55
10A	55
15A	55

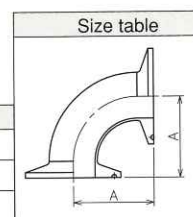

One side is available


MINI FERRULE TEE

Material 316L



One side and two sides are available

SIZE	A
8A	55
10A	55
15A	55

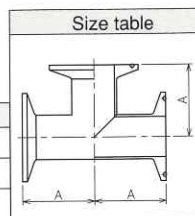


MINI FERRULE REDUCER

Material 316L



Eccentric type is available

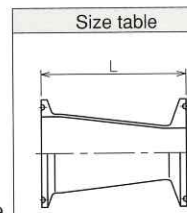


SIZE	L
1.5S×15A	76.1
1.5S×10A	76.1
1.5S×8A	76.1
1S×15A	76.1
1S×10A	76.1
1S×8A	76.1
15A×10A	72.1
15A×8A	72.1
10A×8A	72.1

MINI 3K CLAMP

Material 304



SIZE	D	A	B
8A	45	77	75
10A	45	77	75
15A	45	77	75

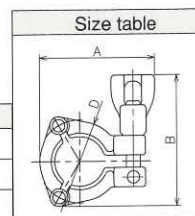

MINI FERRULE GASKET

Material NBR/EPDM/
Silicon/FPM/PTFE



SIZE	A
8A	34
10A	34
15A	34

