

SANITARY FITTINGS CLAMP·HANGER·GASKET **CONSUSS**

2L LOW PRESSURE CLAMP Material 304



SIZE	D	A	B
1S	60	94	90
1.25S	60	94	90
1.5S	60	94	90
2S	75	110	105
2.5S	90	130	108
3S	104	144	114
3.5S	※	※	※
4S	131	172	129

2H HIGH PRESSURE CLAMP Material 304



ISO size is available

SIZE	D	A	B
1S	66	97	88
1.25S	66	97	88
1.5S	66	97	88
2S	80	109	93
2.5S	94	128	98
3S	103	143	106
3.5S	※	※	※
4S	135	173	126

3K CLAMP (SANITARY SIZE) Material 304



SIZE	D	A	B
1S	65	88	92
1.25S	65	88	92
1.5S	65	88	92
2S	79	100	98
2.5S	92	115	105
3S	106	131	111
3.5S	※	※	※
4S	135	162	130

3K CLAMP (ISO SIZE) Material 304



Flange angle: 20°

SIZE	D	A	B
20A	65	88	92
25A	65	88	92
32A	※	※	※
40A	79	100	92
50A	92	115	105
65A	106	131	111
80A	119	138	130
90A	135	162	130
100A	150	165	140
125A	175	190	150
150A	205	220	170
200A	255	280	190

2D CLAMP Material 304



ISO size is available

SIZE	D	A
1S	64	78
1.25S	64	78
1.5S	64	78
2S	77	92
2.5S	91	108
3S	105	122
3.5S	※	※
4S	136	153

PIPE HANGER (SANITARY SIZE) Material 304



Connection screw:
PF1/2"·M10·W3/8"
and etc...

SIZE	D	A
1S	25.4	59
1.25S	※	※
1.5S	38.1	81
2S	50.8	97
2.5S	63.5	111
3S	76.3	124
3.5S	※	※
4S	※	※


PIPE HANGER (ISO SIZE) Material 304



Connection screw:
PF1/2" and etc...

SIZE	D	A
15A	21.7	68
20A	27.2	68
25A	34.0	79
32A	※	※
40A	48.6	94
50A	60.5	108
65A	※	※
80A	89.1	140
90A	101.6	150
100A	114.3	165
125A	139.8	190
150A	165.2	215
200A	216.3	268

FERRULE GASKET (SANITARY SIZE) Material NBR/EPDM/Silicon/ FPM/PTFE/PTFE SAND

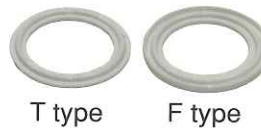

T type F type

SIZE	A1	A2
1S	50.5	52.5
1.25S	50.5	52.5
1.5S	50.5	52.5
2S	64	67
2.5S	77.5	80.5
3S	91	95
3.5S	106	110
4S	119	123

FERRULE GASKET (ISO SIZE) Material NBR/EPDM/ Silicon/FPM/PTFE



SIZE	A
20A	50.5
25A	50.5
32A	58
40A	64
50A	77.5
65A	91
80A	106
90A	119
100A	130
125A	155
150A	183
200A	233.5

L TYPE GASKET Material NBR/EPDM/Silicon/ FPM/PTFE/PTFE SAND



Suitable for union fittings

SIZE	A
1S	32.5
1.25S	39.5
1.5S	46.0
2S	59.5
2.5S	73.2
3S	86.5
3.5S	99.5
4S	112.5