


PTエルボ・ブッシュ めっき付シリーズ


PT ELBOW・TEE'S

PT チーズ (ニッケルめっき仕様) PT TEE'S

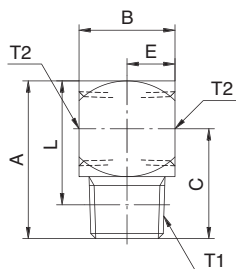


型式 Model	A	二面幅 Spanner Flats B	C	E	L	ねじサイズ Thread		重量 Weight (g)
						T1	T2	
PT-1F-1M-N	22.0	14.0	15.0	7.0	18.0	R1/8	Rc1/8	17.5
PT-1F-2M-N	25.0	14.0	18.0	7.0	19.0	R1/4	Rc1/8	21.3
PT-2F-2M-N	28.0	17.0	19.5	8.5	22.0	R1/4	Rc1/4	28.4
PT-2F-3M-N	29.0	17.0	20.5	8.5	22.6	R3/8	Rc1/4	34.2
PT-3F-3M-N	34.0	22.0	23.0	11.0	27.6	R3/8	Rc3/8	61.3
PT-3F-4M-N	37.0	22.0	26.0	11.0	29.0	R1/2	Rc3/8	69.7

ニップル (ニッケルめっき仕様) NIPPLE (NICKEL-PLATED)

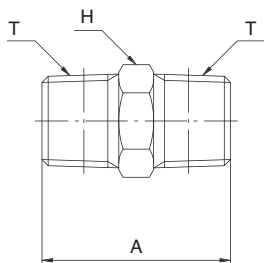

型式 Model	A	二面幅 Spanner Flats H	ねじサイズ Thread T	重量 Weight (g)
N-1M-1M-N	21.0	12.0	R1/8	8.9
N-2M-2M-N	27.0	14.0	R1/4	20.1
N-3M-3M-N	31.0	19.0	R3/8	37.0
N-4M-4M-N	38.0	23.0	R1/2	65.3

異径ニップル (ニッケルめっき仕様) DIFFERENCE NIPPLE (NICKEL-PLATED)

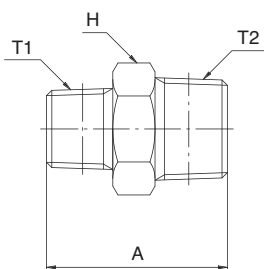

型式 Model	A	二面幅 Spanner Flats H	ねじサイズ Thread		重量 Weight (g)
			T1	T2	
D-1M-2M-N	24.0	14.0	R1/8	R1/4	16.5
D-2M-3M-N	30.0	19.0	R1/4	R3/8	34.3
D-3M-4M-N	35.0	23.0	R3/8	R1/2	56.6
D-2M-4M-N	34.0	23.0	R1/4	R1/2	52.6