
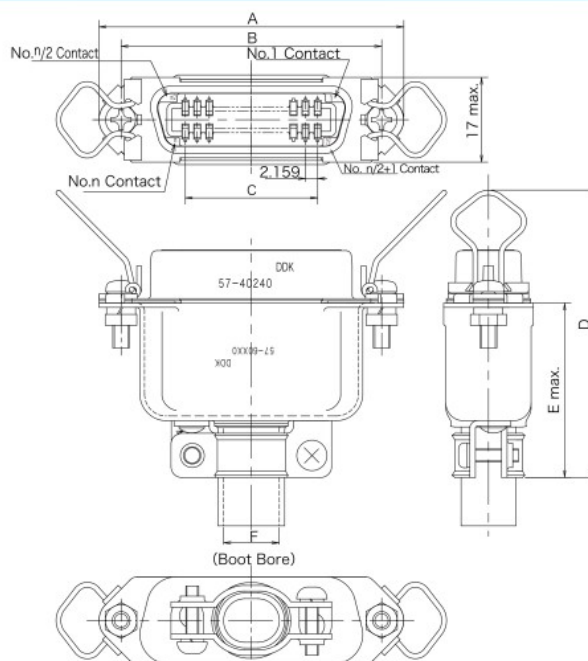


▶ 57-60 Type : Recsptacle for Cable

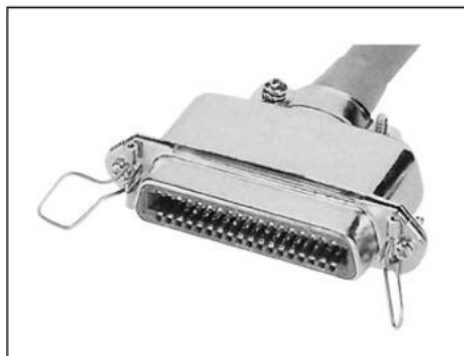


Number of Contact	Part Number (Solder Cup)	Dimensions					
		A	B	C	D	E	F
14	57-60140(R1)	43.9	36.0	12.954	56.7	32.5	6.5×9.8
24	57-60240(R1)	54.7	46.8	23.749	56.2	32.1	11.1×9.8
36	57-60360(R1)	67.7	59.7	36.703	58.2	34.1	13.9×9.8
50	57-60500(R1)	82.8	74.9	51.816	60.5	36.5	17.0×9.8

▶ Dust Cover


- Material : Polythene (PE) / Blue (for Plug), Red (for Receptacle)

for Plug (57-10,57-30)

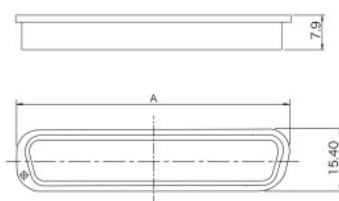

Number of Contact	Part Number	A
14	57-14P	29.6
24	57-24P	40.4
36	57-36P	53.2
50	57-50P	68.6

for Receptacle (57-20, 57-40, 57-60)

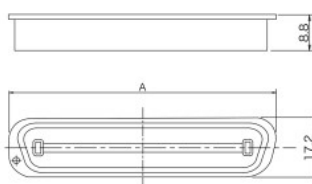

Number of Contact	Part Number	A
14	57-14S	30.0
24	57-24S	42.0
36	57-36S	53.8
50	57-50S	69.0