

004-1 / 004-2 / 004-3 / 004-4 / 004-6

RING SET (mm. size / inch size)

SURFACE TREATMENT : Black parkerized finish / PACKAGE : Vinyl kit with header



004-3

004-6

004 series is a key chain style set that prevent from misplacing wrenches.

Item No.	Pcs.	H								Inner	D×W×H	g		
004-1	8	1.5	2	2.5	3	4	5	5.5	6	12	225×165×55	1,474		
004-2	8	2	2.5	3	4	5	6	8	10	12	225×165×75	3,272		
004-3	10	1.5	2	2.5	3	4	5	5.5	6	8	10	12	225×165×75	3,589
004-4	8	1/16	5/64	3/32	1/8	5/32	3/16	7/32	1/4	12	225×165×55	1,444		
004-6	10	1/16	5/64	3/32	1/8	5/32	3/16	7/32	1/4	5/16	3/8	12	225×165×75	3,355

004-2NP / 004-5NP

RING SET (mm. size / inch size)

SURFACE TREATMENT : Nickel plated / PACKAGE : Slide blister pack



004-2NP

Item No.	Pcs.	H								Inner	D×W×H	g
004-2NP	8	2	2.5	3	4	5	6	8	10	10	230×220×77	2,798
004-5NP	8	3/32	1/8	5/32	3/16	7/32	1/4	5/16	3/8	10	230×220×77	2,873

HEX KEY WRENCH BOREHOLED

001H-S6

DOOR HOLDER SET (mm. size)

SURFACE TREATMENT : Nickel plated / PACKAGE : Slide blister pack




001H-S6

Item No.	Pcs.	H						Inner	D×W×H	g
001H-S6	6	2	2.5	3	4	5	6	10	165×153×102	1,150

001- * H

INDIVIDUAL (mm. size)

SURFACE TREATMENT : Nickel plated / PACKAGE : Bulk pack

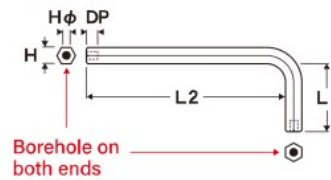

Borehole on both ends

Item No.	H	L1	L2	Hφ	DP	Inner	D×W×H	g
001-2H	2	12	56	1.0	1.5	10	126×65×32	50
001-2.5H	2.5	15	60	1.3	2.0	10	126×65×32	61
001-3H	3	20	65	1.5	3.0	10	126×65×32	80
001-4H	4	25	72	2.0	3.0	10	126×65×32	132
001-5H	5	28	80	2.5	3.5	10	162×68×35	212
001-6H	6	32	90	3.3	5.0	10	162×68×35	322
001-8H	8	36	100	4.7	6.0	10	162×68×35	602
001-10H	10	40	112	5.7	7.0	10	150×100×40	1,052

As tamper-proof (Tamper-resistant) hex screws are often custom-made products, there are occasionally types of screws that have larger protrusions. Please note that EIGHT TOOL borehole hex wrenches do not support such screws.



※Tamper-resistant screw



Please be sure to read "Attention on use" in the appendix.

EXCELLENT

STANDARD

TORX®

IOB&Co.

L TYPE

KNIFE TYPE

SCREW DRIVER TYPE

T-HANDLE TYPE

SOCKET BIT TYPE

BIT TYPE