


Male Elbow KLN

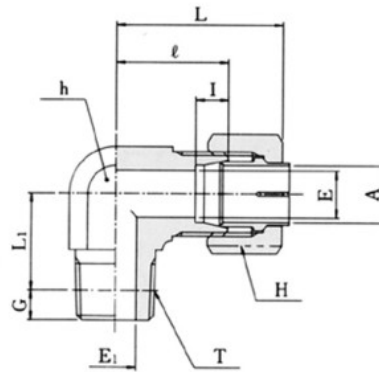

unit: mm

Part No.	Tube OD A	(R) T	E	E ₁	Gauge Length G	Flats h	Hex. H	I	ℓ	Approx. L	Approx. L ₁	Weight (kg)
KLN06-010CE	6	⅛	4.5	4.5	3.97	12	12	5.5	17	26.3	14.5	0.027
KLN06-020CE	6	¼	4.5	7	6.01	14	12	5.5	17	26.3	17	0.035
KLN08-010CE	8	⅛	6	4.5	3.97	12	14	5.5	17.5	27.5	15	0.029
KLN08-020CE	8	¼	6	7	6.01	14	14	5.5	17.5	27.5	18	0.038
KLN10-020CE	10	¼	8	7	6.01	14	17	5.5	20	30	18	0.046
KLN10-030CE	10	⅜	8	9	6.35	17	17	5.5	21	31	19.7	0.066
KLN12-020CE	12	¼	10	7	6.01	17	19	6	21	31	19	0.064
KLN12-030CE	12	⅜	10	9	6.35	17	19	6	21	31	19.7	0.071
KLN12-040CE	12	½	10	12	8.16	24	19	6	24	34	25.8	0.134
KLN16-030CE	16	⅜	13	9	6.35	24	27	8	28	40.6	24.7	0.167
KLN16-040CE	16	½	13	12	8.16	24	27	8	28	40.6	25.8	0.167
KLN20-040CE	20	½	17	12	8.16	27	30	8	30.5	44.8	27.8	0.230
KLN20-060CE	20	¾	17	16	9.53	30	30	8	30.5	44.8	28.5	0.258
KLN25-060CE	25	¾	22	16	9.53	36	36	9	35.5	50.3	31.5	0.397
KLN25-080CE	25	1	22	22	10.39	36	36	9	35.5	50.3	33.6	0.412
KLN30-060CE	30	¾	26	16	9.53	41	41	9	39.5	54.8	34.5	0.550
KLN30-080CE	30	1	26	22	10.39	41	41	9	39.5	54.8	36.6	0.555
KLN30-100CE	30	1¼	26	31	12.7	46	41	9	41	56.3	42.3	0.670