


Female Seat Hose Connection Union Elbow KLE

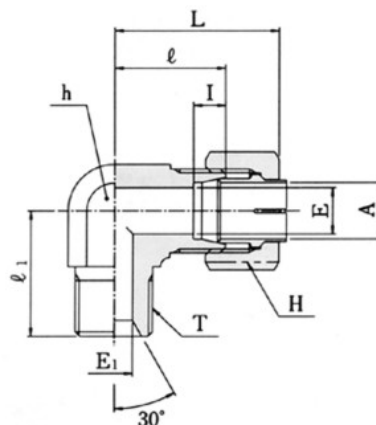

unit: mm

Part No.	Tube OD A	(G) T	E	E ₁	Flats h	Hex. H	I	l ₁	l	Approx. L	Weight (kg)
KLE08-020CE	8	¼	6	5.5	14	14	5.5	24	17.5	27.5	0.042
KLE08-030CE	8	⅜	6	8	17	14	5.5	26.5	20.5	30.5	0.063
KLE10-020CE	10	¼	8	5.5	14	17	5.5	24	20	30	0.048
KLE10-030CE	10	⅜	8	8	17	17	5.5	26.5	21	31	0.067
KLE12-020CE	12	¼	10	5.5	17	19	6	25	21	31	0.067
KLE12-030CE	12	⅜	10	8	17	19	6	26.5	21	31	0.073
KLE12-040CE	12	½	10	10	24	19	6	33	24	34	0.141
KLE16-030CE	16	⅜	13	8	24	27	8	30	28	40.6	0.164
KLE16-040CE	16	½	13	10	24	27	8	33	28	40.6	0.179
KLE20-040CE	20	½	17	10	27	30	8	35	30.5	44.8	0.174
KLE20-060CE	20	¾	17	16	30	30	8	38	30.5	44.8	0.267
KLE25-060CE	25	¾	22	16	36	36	9	41	35.5	50.3	0.407
KLE25-080CE	25	1	22	21.5	36	36	9	43	35.5	50.3	0.413
KLE30-060CE	30	¾	26	16	41	41	9	44	39.5	54.8	0.550
KLE30-080CE	30	1	26	21.5	41	41	9	46	39.5	54.8	0.570