


ナールドサムノブ TKS, TKN

TKS-sus, TKN-sus

RoHS指令適合品

Knurled Thumb Knobs TKS,TKN

TKS-sus,TKN-sus

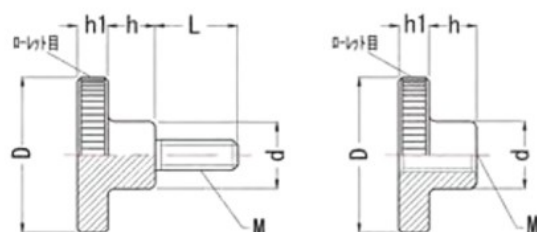

- 材 鋼材SUM22 Steel
- 表 クロムメッキ Chrome plated
- 材 ステンレスSUS303 Stainless

おねじタイプ

Unit : mm

品番	品番	M	L	D	H	d	h	h1	(g)
TKS- 4× 6	TKS- 4× 6-sus	M 4×P0.7	6	16	8.5	8	6.0	2.5	9
TKS- 4×10	TKS- 4×10-sus		10						10
TKS- 4×16	TKS- 4×16-sus		16						10
TKS- 5×10	TKS- 5×10-sus	M 5×P0.8	10	20	11.5	10	7.5	4.0	15
TKS- 5×15	TKS- 5×15-sus		15						18
TKS- 5×20	TKS- 5×20-sus		20						20
TKS- 6×15	TKS- 6×15-sus	M 6×P1.0	15	24	15.0	12	10.0	5.0	25
TKS- 6×20	TKS- 6×20-sus		20						27
TKS- 6×25	TKS- 6×25-sus		25						29
TKS- 6×30	TKS- 6×30-sus		30						30
TKS- 8×20	TKS- 8×20-sus	M 8×P1.25	20	30	18.0	16	12.0	6.0	60
TKS- 8×25	TKS- 8×25-sus		25						63
TKS- 8×30	TKS- 8×30-sus		30						65
TKS-10×25	TKS-10×25-sus	M10×P1.5	25	36	23.0	20	15.0	8.0	115
TKS-10×30	TKS-10×30-sus		30						119
TKS-10×40	TKS-10×40-sus		40						125

めねじタイプ

Unit : mm

品番	品番	M	D	H	d	h	h1	(g)
TKN- 4	TKN- 4-sus	M 4×P0.7	16	8.5	8	6.0	2.5	7
TKN- 5	TKN- 5-sus	M 5×P0.8	20	11.5	10	7.5	4.0	15
TKN- 6	TKN- 6-sus	M 6×P1.0	24	15.0	12	10.0	5.0	25
TKN- 8	TKN- 8-sus	M 8×P1.25	30	18.0	16	12.0	6.0	45
TKN-10	TKN-10-sus	M10×P1.5	36	23.0	20	15.0	8.0	90