


# FBN2062B to 2082B



## FBN Double Pitch Sprocket for R Rollers New JIS Keyway Specification

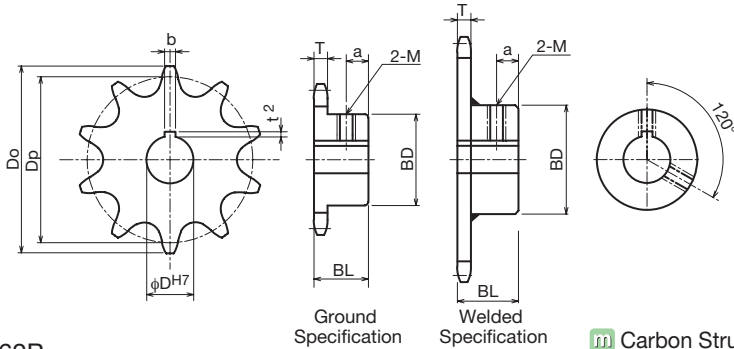

### FBN2062B

- Chain ..... No.C2062H
- Chain Pitch ..... (P)38.10mm
- Roller Link Inner Width ..... (W)12.70mm

- Roller Outside Diameter ... (Dr)22.23mm
- Tooth Width ..... (T)11.7 mm

**m** Carbon Structural Steel  
Ground Specification

☆ **m** Common Steel  
Welded Specification

Type	No. of Active Teeth	φDH7	Outer Diameter Do	Pitch Diameter Dp	Boss Diameter BD	Boss Length BL	a	Weight kg	¥
<b>FBN 2062B</b>	10	30 35 40 45	140	123.29	80	45	12	2.5	
	11	30 35 40 45	153	135.23	80	45	12	2.6	
	12	30 35 40 45	165	147.21	80	45	12	2.8	
	☆13	30 35 40 45	177	159.20	83	45	12	3.1	
	☆16	30 35 40 45	214	195.29	83	45	12	4.2	
	☆20	30 35 40 45	263	243.55	83	45	12	6.0	

### FBN2082B

- Chain ..... No.C2082H
- Chain Pitch ..... (P)50.80mm
- Roller Link Inner Width ..... (W)15.88mm

- Roller Outside Diameter ... (Dr)28.58mm
- Tooth Width ..... (T)14.6 mm

**m** Common Steel  
Welded Specification

Type	No. of Active Teeth	φDH7	Outer Diameter Do	Pitch Diameter Dp	Boss Diameter BD	Boss Length BL	a	Weight kg	¥
<b>FBN 2082B</b>	11	30 35 40 45	204	180.31	107	45	12	4.42	
	12	30 35 40 45	220	196.28	107	45	12	4.49	

### Shaft Hole Machined Specification

Shaft hole diameter D	Keyway b x t <sup>2</sup>	Set Screw M
18 - 22	6 x 2.8	6
24 - 30	8 x 3.3	8
32 - 38	10 x 3.3	8
40 - 42	12 x 3.3	8
45 - 50	14 x 3.8	10



Order Method

Sprocket No.  and Quantity



Postage

Same-day shipping



Guide

\* Since we also manufacture sizes other than those in the catalog, and machine shaft holes/keys/taps, etc., depending on your request, please contact our company's sales office for details.

- Semi-F Series & FITLINK
- Roller Chains
- Chain Accessories
- Idlers & Tensioners
- Sprockets
- Oilless Bushings
- Transmission Accessories
- Conveyor Chains/Sprockets
- Chain Couplings
- Roller Chains
- Triple Speed/Center Tension Chains
- Timing Belts/Pulleys/Ranges
- Shaft Collars
- Pinions/Racks/Miter Gears
- Imperfect Products