


## Tube End (Small Diameter)

Standard length: 200, 400, 600, 800, 1000mm

Material: Hose: SUS316L、 Flange: SUS316L

Helium leak rate:  $< 1 \times 10^{-9} \text{Pa} \cdot \text{m}^3/\text{sec}$

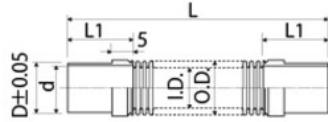

### List of Tube End

Code	Size	I.D.	O.D.	D	d	L1	Thickness	Minimum bending radius	L (Production length)		L (With blade)	
									Minimum	Maximum	Minimum	Maximum
MTT-04	$\phi 6.35$	5.4	8.9	6.35	4.5	25	0.15	15	75	3,000	150	3,000
MTT-06	$\phi 9.52$	10.0	13.8	9.52	7	30	0.15	25	85	3,000	150	3,000
MTT-08	$\phi 12.7$	15.0	19.4	12.7	10	35	0.15	30	95	3,000	150	3,000

In case of bending this hose, longer straight length than the hose outer diameter is required.



1100 Anadaira Sutama-cho Hokuto Yamanashi, Japan  
Sales Department FAX 0551-42-5556 e-mail [mpccom@mirapro.co.jp](mailto:mpccom@mirapro.co.jp)