

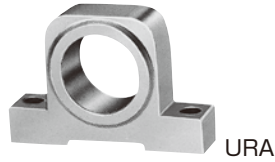
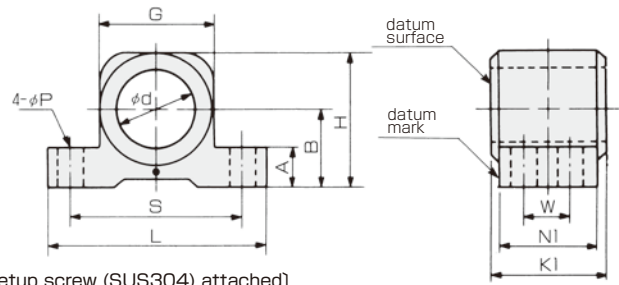


# Type URA (Force fit)

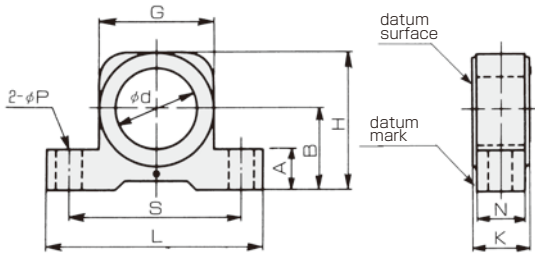

# Type URW (Force fit)

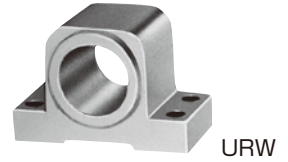

(setup screw (SUS304) attached)

※Two blocks are paired as one set for type URA in order to keep the center height accuracy(dimension B) at installation.

## Dimension Table

Type URA	Type URW	$\phi d_{Js6}$	$B_{\pm 0.02}$	H	A	L	G	S	$\phi P$	K	$K_1$	N	$N_1$	W	M Setup screw
URA-203	URW-203	3	8	13	4	24	10	18	3.5	6	12	5.6	11.6	6	M3×10L
URA-204	URW-204	4													
URA-205	URW-205	5													
URA-306	URW-306	6	9	15	5	26	12	20	3.5	7	14	6.0	13.0	7	M3×10L
URA-307	URW-307	7													
URA-408	URW-408	8	11	19	6	32	16	25	3.5	8	16	7.0	15.0	8	M3×12L
URA-409	URW-409	9													
URA-410	URW-410	10													
URA-511	URW-511	11	14	24	7	38	20	30	4.5	10	20	8.5	18.5	10	M4×15L
URA-512	URW-512	12													
URA-513	URW-513	13													
URA-514	URW-514	14													
URA-615	URW-615	15	18	31	9	48	26	38	5.5	12	24	10	22.0	12	M5×18L
URA-616	URW-616	16													
URA-617	URW-617	17													
URA-618	URW-618	18													
URA-619	URW-619	19													
URA-720	URW-720	20	20	35	10	52	30	42	5.5	14	28	12	26.0	14	M5×20L
URA-721	URW-721	21													
URA-722	URW-722	22													

# Type BBA



Block for height adjustment

※Two blocks are paired as one set for type BBA



# Type BBW

Block for height adjustment

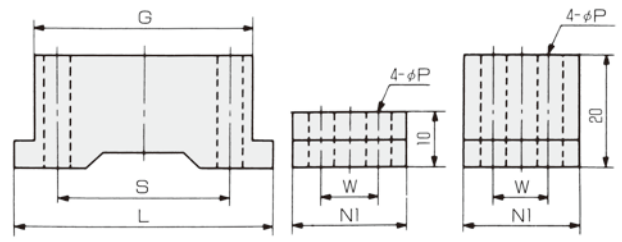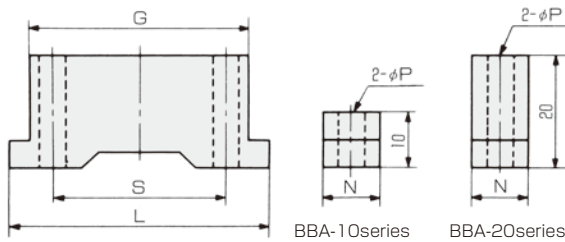

(setup screw (SUS304) attached)

BBW-10series BBW-20series

## 寸法表

Type	S	2-φP	L	G	N	Setup screw		Block to be applied	
BBA-10series	BBA-20series					BBA-10series	BBA-20series		
BBA-102	BBA-202	18	3.5	32	26	8	M3×20L	M3×30L	UPA·URA-203·204·205
BBA-103	BBA-203	20	3.5				M3×20L	M3×30L	UPA·URA-306·307
BBA-104	BBA-204	25	3.5	45	38	11	M3×25L	M3×35L	UPA·URA-408·409·410
BBA-105	BBA-205	30	4.5				M4×25L	M4×35L	UPA·URA-511·512·513·514
BBA-106	BBA-206	38	5.5	60	52	15	M5×30L	M5×40L	UPA·URA-615·616·617·618
BBA-107	BBA-207	42	5.5				M5×30L	M5×40L	UPA·URA-719·720·721·722

## 寸法表

Type	S	W	4-φP	L	G	N1	Setup screw		Block to be applied
BBW-10series	BBW-20series						BBW-10series	BBW-20series	
BBW-102	BBW-202	18	6	32	26	15	M3×20L	M3×30L	UPW·URW-203·204·205
BBW-103	BBW-203	20	7				M3×20L	M3×30L	UPW·URW-306·307
BBW-104	BBW-204	25	8	45	38	21	M3×25L	M3×35L	UPW·URW-408·409·410
BBW-105	BBW-205	30	10				M4×25L	M4×35L	UPW·URW-511·512·513·514
BBW-106	BBW-206	38	12	60	52	29	M5×30L	M5×40L	UPW·URW-615·616·617·618
BBW-107	BBW-207	42	14				M5×30L	M5×40L	UPW·URW-719·720·721·722