





Outer surface: grinding finish / SUS304 / Total length 50L-3000L / 9 sizes  
Cut by preferred length for sale upon request (cut length=  $L_0^{+1.0}$ )

Outer diameter x thickness	Outer diameter tolerance	50L	100L	150L	200L	250L	300L	350L	2000L	3000L
		Part No.	Part No.	Part No.	Part No.	Part No.	Part No.	Part No.	Part No.	Part No.
φ 6×0.5	0~ -0.03	SS0605-	SS0605-	SS0605-	SS0605-	SS0605-	SS0605-	SS0605-	SS0605-	—
φ 8×0.8		SS0808-	SS0808-	SS0808-	SS0808-	SS0808-	SS0808-	SS0808-	SS0808-	—
φ 9×0.8		SS0908-	SS0908-	SS0908-	SS0908-	SS0908-	SS0908-	SS0908-	SS0908-	—
φ 10×0.8		SS1008-	SS1008-	SS1008-	SS1008-	SS1008-	SS1008-	SS1008-	SS1008-	—
φ 12×0.8	0~ -0.05	—	SS1208-	SS1208-	SS1208-	SS1208-	SS1208-	SS1208-	SS1208-	—
φ 13×0.8		—	SS1308-	SS1308-	SS1308-	SS1308-	SS1308-	SS1308-	SS1308-	—
φ 13×1.2		—	SS1312-	SS1312-	SS1312-	SS1312-	SS1312-	SS1312-	SS1312-	—
φ 15×1.5		—	SS1515-	SS1515-	SS1515-	SS1515-	SS1515-	SS1515-	SS1515-	—
φ 16×1.5	±0.05	—	SS1615-	SS1615-	SS1615-	SS1615-	SS1615-	SS1615-	SS1615-	—
φ 19×1.0		—	SS1910-	SS1910-	SS1910-	SS1910-	SS1910-	SS1910-	SS1910-	—
φ 19×2.0		—	SS1920-	SS1920-	SS1920-	SS1920-	SS1920-	SS1920-	SS1920-	—
φ 20×2.0		0~ -0.05	—	—	—	—	—	—	—	SS2020
φ 25×1.0	±0.05	—	—	—	—	—	—	—	SS2510	—
φ 25×2.0		—	—	—	—	—	—	—	SS2520	—
φ 30×2.5	0~ -0.1	—	—	—	—	—	—	—	SS302520	SS302530
φ 32×2.5		—	—	—	—	—	—	—	SS322520	SS322530
φ 35×2.5		—	—	—	—	—	—	—	SS352520	SS352530

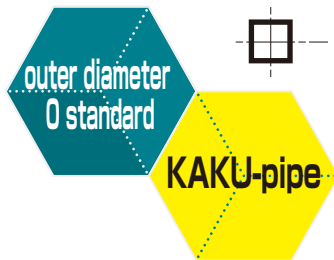

Outer surface: hairline finish SUS304 / Total length 200L-1000L / 5 sizes

dimension		200L	300L	350L	550L	1000L
side x thickness	side dimension tolerance	Part No.	Part No.	Part No.	Part No.	Part No.
□ 6×0.8	0~-0.1	SS06	SS06	SS06	SS06	SS06
□ 8×0.8		SS08	SS08	SS08	SS08	SS08
□ 9×0.8		SS09	SS09	SS09	SS09	SS09
□ 10×1.0		SS10	SS10	SS10	SS10	SS10
□ 12×1.0		SS12	SS12	SS12	SS12	SS12
□ 13×1.0		SS13	200K	300K	350K	550K
□ 15×1.0	0~-0.12	SS15	SS15	SS15	SS15	SS15
□ 16×1.0		SS16	SS16	SS16	SS16	SS16
□ 19×1.2		SS19	SS19	SS19	SS19	SS19
□ 20×1.2	0~-0.15	SS20	SS20	SS20	SS20	SS20
□ 25×1.2		SS25	SS25	SS25	SS25	SS25

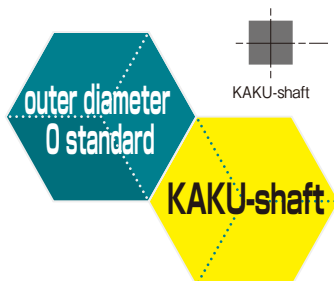

Outer surface: hairline finish SUS304 / Total length 200L-2050L / 6 sizes  
Cut by preferred length for sale upon request (cut length=  $L_0^{+1.0}$ )

dimension		200L	300L	350L	550L	1050L	2050L
side x thickness	side dimension tolerance	Part No.	Part No.	Part No.	Part No.	Part No.	Part No.
※ □ 6	0~ -0.1	SS06	SS06	SS06	SS06	SS06	—
※ □ 8		SS08	SS08	SS08	SS08	SS08	—
※ □ 9		SS09	SS09	SS09	SS09	SS09	—
□ 10		SS10	SS10	SS10	SS10	SS10	SS10
□ 12		SS12	SS12	SS12	SS12	SS12	SS12
□ 13		SS13	200S	300S	350S	550S	1050S
□ 15	2050S	SS15	SS15	SS15	SS15	SS15	SS15
□ 16		SS16	SS16	SS16	SS16	SS16	SS16
□ 19		SS19	SS19	SS19	SS19	SS19	SS19
□ 20		SS20	SS20	SS20	SS20	SS20	SS20
□ 25		SS25	SS25	SS25	SS25	SS25	SS25

※ □6・8・9 = No hairline finish