

Self-Lubricating Keeper Plates – Metric

Product Features

These self-lubricating metric Keeper plates are 30mm thick and fully meet the NAAMS standard. They are manufactured from hardened steel with oil-impregnated graphite plugs. The plates are available with or without mounting holes.




MATERIALS:

- High quality carburized steel with oil-impregnated graphite plugs. They are precision ground and hardened to Rc56-62.

MOUNTING SCREWS:

- M16 SDCS recommended for mounting with 17.5mm drill thru in plate.

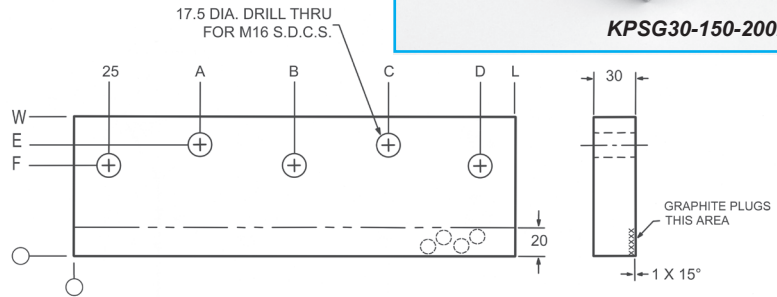

Width W (mm)	Length L (mm)	With Mounting Holes		Without Mounting Holes		Mount'g. Hole Quantity	Mounting Hole Locations					
		Part Number	NAAMS Code	Part Number	NAAMS Code		A (mm)	B (mm)	C (mm)	D (mm)	E (mm)	F (mm)
75	200	KPSG30-75-200F	—	KPSG30-75-200N	—	3	100	—	—	175	55	40
	250	KPSG30-75-250F	—	KPSG30-75-250N	—	3	125	—	—	225		
	315	KPSG30-75-315F	—	KPSG30-75-315N	—	5	90	158	225	290		
	350	KPSG30-75-350F	—	KPSG30-75-350N	—	5	100	175	250	325		
	400	KPSG30-75-400F	—	KPSG30-75-400N	—	5	115	200	285	375		
	450	KPSG30-75-450F	—	KPSG30-75-450N	—	5	125	225	325	425		
100	200	KPSG30-100-200F	R211020	KPSG30-100-200N	R221020	3	100	—	—	175	80	55
	250	KPSG30-100-250F	R211025	KPSG30-100-250N	R221025	4	90	—	160	225		
	315	KPSG30-100-315F	R211031	KPSG30-100-315N	R221031	5	90	158	225	290		
	350	KPSG30-100-350F	R211035	KPSG30-100-350N	R221035	5	100	175	250	325		
	400	KPSG30-100-400F	R211040	KPSG30-100-400N	R221040	5	115	200	285	375		
	450	KPSG30-100-450F	R211045	KPSG30-100-450N	R221045	5	125	225	325	425		
125	200	KPSG30-125-200F	R211220	KPSG30-125-200N	R221220	3	100	—	—	175	105	65
	250	KPSG30-125-250F	R211225	KPSG30-125-250N	R221225	4	90	—	160	225		
	315	KPSG30-125-315F	R211231	KPSG30-125-315N	R221231	5	90	158	225	290		
	350	KPSG30-125-350F	R211235	KPSG30-125-350N	R221235	5	100	175	250	325		
	400	KPSG30-125-400F	R211240	KPSG30-125-400N	R221240	5	115	200	285	375		
	450	KPSG30-125-450F	R211245	KPSG30-125-450N	R221245	5	125	225	325	425		
150	200	KPSG30-150-200F	R211520	KPSG30-150-200N	R221520	3	100	—	—	175	130	65
	250	KPSG30-150-250F	R211525	KPSG30-150-250N	R221525	4	90	—	160	225		
	315	KPSG30-150-315F	R211531	KPSG30-150-315N	R221531	5	90	158	225	290		
	350	KPSG30-150-350F	R211535	KPSG30-150-350N	R221535	5	100	175	250	325		
	400	KPSG30-150-400F	R211540	KPSG30-150-400N	R221540	5	115	200	285	375		
	450	KPSG30-150-450F	R211545	KPSG30-150-450N	R221545	5	125	225	325	425		