


# SB Type

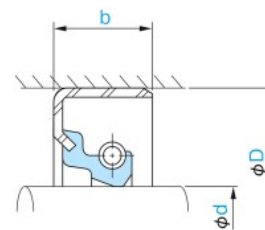

SB type

- The sectional view on the right shows the typical profile of the seal type.
- Please refer to page 25 for the respective advantages and disadvantages of Types B and C.
- Check the guide to allowable operating conditions on pages 10 and 11 for relevant information on the seal selected before use.
- If there is an “\*” at the end of the part number, as this indicates that an SUS spring specification is available, we ask that you refer to the introduction on SUS spring specifications on page 152.

■ When ordering, please indicate the NOK part number and the relevant dimensions.  
**Order Example** NOK Part Number: AB 0090 E0  
 Type: SB, Shaft diameter: 7, Outside diameter: 20, Width: 7

Dimensions			Part Number			
Shaft diameter d	Outside diameter D	Width b	Nitrile (NBR) <small>shaft diameter of 150 mm or less: A727 shaft diameter over 150 mm: A941</small>	Acrylic (ACM) T303	Silicon (VMQ) S728	Fluorocarbon (FKM) F585
7	20	7	AB 0090 E0	—	—	—
8	18	7	AB 0145 E0	—	—	—
8	18	9	AB 0147 F0	—	—	—
8	22	7	AB 0158 E0	—	—	AB 0158 A3
9	22	7	AB 0205 E0	—	—	—
10	20	7	AB 0260 E0	—	—	—
10	21	8	AB 0267 E0	—	—	—
10	22	8	AB 0271 F0	—	—	—
10	25	7	AB 0279 E0	—	—	AB 0279 A3
10	30	7	AB 0288 E0	—	—	—
11	22	7	AB 0308 E2	—	—	—
12	22	7	AB 0371 E0	—	—	—
12	25	7	AB 0382 E0	—	—	AB 0382 A5
12	28	7	AB 0387 E0	—	—	—
12	30	9	AB 0393 E0	—	—	—
12	32	6	AB 0398 E0	—	—	—
13	25	7	AB 0473 E1	—	—	—
13	28	7	AB 0478 E0	—	—	—
14	24	6	AB 0514 E0	—	—	—
14	28	7	AB 0526 E0	—	—	—
15	24	7	AB 0584 E0	—	—	—
15	25	7	AB 0588 F0	—	—	—
15	28	7	AB 0592 E0	—	—	—
15	30	7	AB 0598 E0	—	—	AB 0598 A4
15	32	7	AB 0603 E0	—	—	—
15	32	9	AB 0604 E0	—	—	—
15	35	7	AB 0610 E0	—	—	—
16	26	7	AB 0678 E0	—	—	—
16	28	7	AB 0685 E0	—	—	—
16	30	7	AB 0687 E0	—	—	AB 0687 A4
16	35	9	AB 0698 E0	—	—	—
17	28	7	AB 0736 F0	—	—	—
17	30	6	AB 0742 G0	—	—	—
17	30	8	AB 0745 G0	—	—	—
17	32	8	AB 0751 E0	—	—	—
17	35	7	AB 0759 E0	—	—	—
17	35	8	—	—	—	AB 0760 A3
17	38	7	AB 0768 E0	—	—	—
17	40	8	AB 0771 E1	—	—	—
18	30	7	AB 0816 E0	—	—	—
18	30	8	AB 0817 E0	—	—	—
18	35	8	AB 0829 E0	—	—	AB 0829 A3
18	35	9	AB 0831 E0	—	—	—
19	30	8	AB 0864 E0	—	—	—
19	38	7	AB 0880 E0	—	—	—