


Bushing

●Millimeter size type

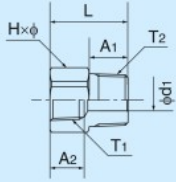

Product number	T ₁ Thread size (RC)	T ₂ Thread size (R)	L (mm)	A ₁ (mm)	A ₂ (mm)	H×φ Width across flat (mm)	d ₁ (mm)	Weight (g)
3A0-4-6-CS	RC1/4	R3/8	29.0	14.0	13.0	17.0×18.5	9.0	—
3A0-6-8-CS	RC3/8	R1/2	34.5	18.0	13.5	22.0×24.5	11.0	—
3A0-8-12-CS	RC1/2	R3/4	40.0	20.0	17.5	30.0×33.0	11.0	—




Socket

●Millimeter size type



Product number	T Thread size (RC)	L (mm)	A (mm)	H×φ Width across flat (mm)	d ₁ (mm)	Weight (g)
330-4-4-CS	RC1/4	30.0	13.0	17.0×18.5	9.0	—
330-6-6-CS	RC3/8	33.0	13.5	19.0×21.0	13.0	—
330-8-8-CS	RC1/2	39.5	17.5	24.0×26.5	17.0	—

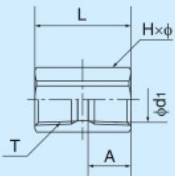

Tubing
Clean tubing
Processed tubing
PushOne fitting
QuickSeal fitting
Clean fitting/Chemifit
Bamboo-shoot fitting
Control switch/Detachable series
Jig/Tool/Accessory
Technical information
Reference