


Elbow type

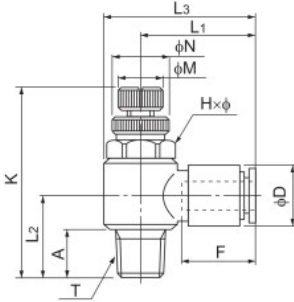

●Millimeter size type

Product number	Applicable tube outer diameter (mm)	T Thread size (R)	L ₁ (mm)	L ₂ (mm)	L ₃ (mm)	K		A (mm)	F Tube insertion length (mm)	H×φ Width across flat (mm)	N (mm)	M (mm)	D (mm)	Effective cross-sectional area (mm ²)	Weight (g)
						Full open (mm)	Full closed (mm)								
ENC4-PT1/8-TR	4	R1/8	22.1	17.7	29.1	46.8	42.0	9.7	13	13.0×14.0	13.0	10.0	9.7	3.0	29.0
ENC6-PT1/8-TR	6	R1/8	22.2	17.7	29.2	46.8	42.0	9.7	15	13.0×14.0	13.0	10.0	12.5	3.5	30.0




Inline type



●Millimeter size type

Product number	Applicable tube outer diameter (mm)	L (mm)	F Tube insertion length (mm)	K		Effective cross-sectional area (mm ²)	Weight (g)
				Full open (mm)	Full closed (mm)		
ENU4	4	39.2	13	29.5	26.9	—	11.0
ENU6	6	46.4	15	43.5	39.8	—	32.0
ENU8	8	54.0	16	47.7	42.1	—	48.0

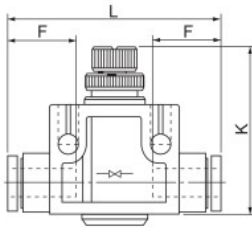


Connector pin



●Connector pin

Product number	Applicable fitting product number
HPN4	ENU4
HPN6	ENU6
	ENU8

Bracket

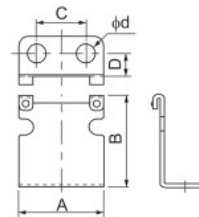

●Bracket

Product number	Applicable fitting product number	A (mm)	B (mm)	C (mm)	D (mm)	d (mm)
BRK4	ENU4	18.0	18.5	10.0	6.5	5.0
BRK6	ENU6	24.0	26.0	14.0	6.5	5.0
BRK8	ENU8	26.0	30.0	14.0	6.5	5.0