


Series AW

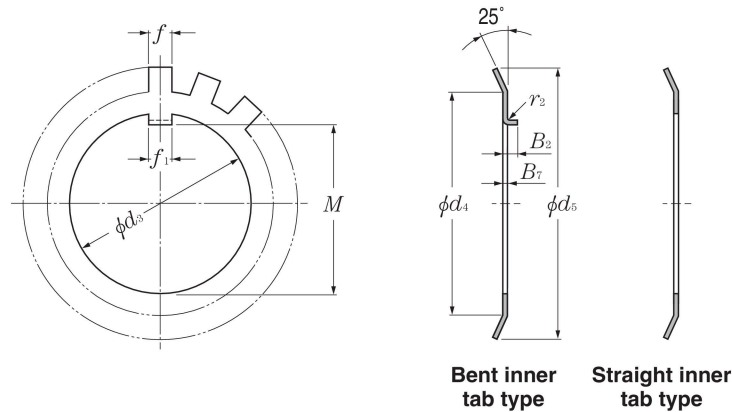

| Bearing numbers | | Dimensions | | | | | | | No. of tabs | | Mass | |
|---------------------|-------------------------|------------|-------|-------|-------|-----|-------|-------|---------------------|-------|----------------------|-------|
| bent inner tab type | straight inner tab type | d_3 | M | f_1 | B_7 | f | d_4 | d_5 | bent inner tab type | | kg | |
| | | | | | | | | | r_2 | B_2 | 100 pieces (approx.) | |
| AW00 | AW00X | 10 | 8.5 | 3 | 1 | 3 | 13.5 | 21 | 0.5 | 2 | 9 | 0.131 |
| AW01 | AW01X | 12 | 10.5 | 3 | 1 | 3 | 17 | 25 | 0.5 | 2 | 11 | 0.192 |
| AW02 | AW02X | 15 | 13.5 | 4 | 1 | 4 | 21 | 28 | 1 | 2.5 | 13 | 0.253 |
| AW03 | AW03X | 17 | 15.5 | 4 | 1 | 4 | 24 | 32 | 1 | 2.5 | 13 | 0.313 |
| AW04 | AW04X | 20 | 18.5 | 4 | 1 | 4 | 26 | 36 | 1 | 2.5 | 13 | 0.35 |
| AW05 | AW05X | 25 | 23 | 5 | 1.2 | 5 | 32 | 42 | 1 | 2.5 | 13 | 0.64 |
| AW06 | AW06X | 30 | 27.5 | 5 | 1.25 | 5 | 38 | 49 | 1 | 3.75 | 13 | 0.78 |
| AW07 | AW07X | 35 | 32.5 | 6 | 1.25 | 5 | 44 | 57 | 1 | 3.75 | 15 | 1.04 |
| AW08 | AW08X | 40 | 37.5 | 6 | 1.25 | 6 | 50 | 62 | 1 | 3.75 | 15 | 1.23 |
| AW09 | AW09X | 45 | 42.5 | 6 | 1.25 | 6 | 56 | 69 | 1 | 3.75 | 17 | 1.52 |
| AW10 | AW10X | 50 | 47.5 | 6 | 1.25 | 6 | 61 | 74 | 1 | 3.75 | 17 | 1.6 |
| AW11 | AW11X | 55 | 52.5 | 8 | 1.5 | 7 | 67 | 81 | 1 | 5.5 | 17 | 1.96 |
| AW12 | AW12X | 60 | 57.5 | 8 | 1.5 | 7 | 73 | 86 | 1.2 | 5.5 | 17 | 2.53 |
| AW13 | AW13X | 65 | 62.5 | 8 | 1.5 | 7 | 79 | 92 | 1.2 | 5.5 | 19 | 2.9 |
| AW14 | AW14X | 70 | 66.5 | 8 | 1.5 | 8 | 85 | 98 | 1.2 | 5.5 | 19 | 3.34 |
| AW15 | AW15X | 75 | 71.5 | 8 | 1.5 | 8 | 90 | 104 | 1.2 | 5.5 | 19 | 3.56 |
| AW16 | AW16X | 80 | 76.5 | 10 | 1.8 | 8 | 95 | 112 | 1.2 | 5.8 | 19 | 4.64 |
| AW17 | AW17X | 85 | 81.5 | 10 | 1.8 | 8 | 102 | 119 | 1.2 | 5.8 | 19 | 5.24 |
| AW18 | AW18X | 90 | 86.5 | 10 | 1.8 | 10 | 108 | 126 | 1.2 | 5.8 | 19 | 6.23 |
| AW19 | AW19X | 95 | 91.5 | 10 | 1.8 | 10 | 113 | 133 | 1.2 | 5.8 | 19 | 6.7 |
| AW20 | AW20X | 100 | 96.5 | 12 | 1.8 | 10 | 120 | 142 | 1.2 | 7.8 | 19 | 7.65 |
| AW21 | AW21X | 105 | 100.5 | 12 | 1.8 | 12 | 126 | 145 | 1.2 | 7.8 | 19 | 8.26 |
| AW22 | AW22X | 110 | 105.5 | 12 | 1.8 | 12 | 133 | 154 | 1.2 | 7.8 | 19 | 9.4 |
| AW23 | AW23X | 115 | 110.5 | 12 | 2 | 12 | 137 | 159 | 1.5 | 7.8 | 19 | 10.8 |
| AW24 | AW24X | 120 | 115 | 14 | 2 | 12 | 138 | 164 | 1.5 | 8 | 19 | 10.5 |
| AW25 | AW25X | 125 | 120 | 14 | 2 | 12 | 148 | 170 | 1.5 | 8 | 19 | 11.8 |
| AW26 | AW26X | 130 | 125 | 14 | 2 | 12 | 149 | 175 | 1.5 | 8 | 19 | 11.3 |
| AW27 | AW27X | 135 | 130 | 14 | 2 | 14 | 160 | 185 | 1.5 | 8 | 19 | 14.4 |
| AW28 | AW28X | 140 | 135 | 16 | 2 | 14 | 160 | 192 | 1.5 | 10 | 19 | 14.2 |
| AW29 | AW29X | 145 | 140 | 16 | 2 | 14 | 171 | 202 | 1.5 | 10 | 19 | 16.8 |
| AW30 | AW30X | 150 | 145 | 16 | 2 | 14 | 171 | 205 | 1.5 | 10 | 19 | 15.5 |
| AW31 | AW31X | 155 | 147.5 | 16 | 2.5 | 16 | 182 | 212 | 1.5 | 10.5 | 19 | 20.9 |
| AW32 | AW32X | 160 | 154 | 18 | 2.5 | 16 | 182 | 217 | 1.5 | 10.5 | 19 | 22.2 |
| AW33 | AW33X | 165 | 157.5 | 18 | 2.5 | 16 | 193 | 222 | 1.5 | 10.5 | 19 | 24.1 |
| AW34 | AW34X | 170 | 164 | 18 | 2.5 | 16 | 193 | 232 | 1.5 | 10.5 | 19 | 24.7 |
| AW36 | AW36X | 180 | 174 | 20 | 2.5 | 18 | 203 | 242 | 1.5 | 10.5 | 19 | 26.8 |
| AW38 | AW38X | 190 | 184 | 20 | 2.5 | 18 | 214 | 252 | 1.5 | 10.5 | 19 | 27.8 |
| AW40 | AW40X | 200 | 194 | 20 | 2.5 | 18 | 226 | 262 | 1.5 | 10.5 | 19 | 29.3 |

1) Uses adapter series H31, H2, H32, H3, and H23.