



Cross-section

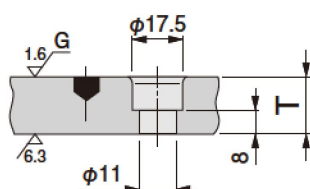


Chamfering


Type A

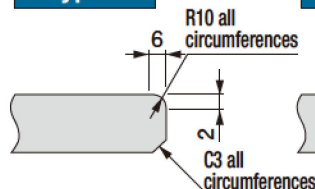

Type B

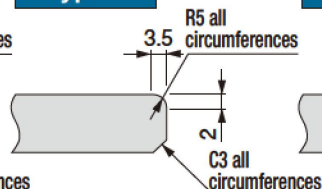

Type C

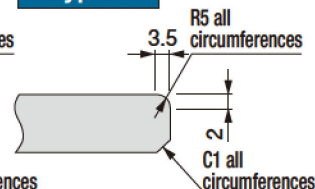

Parts No.	Width		Length		Thickness		Mounting hole intervals						Attach bolts		Chamfering
	W	Tolerance	L	Tolerance	T	Tolerance	W ₁	Tolerance	W ₂	ℓ ₁	Tolerance	ℓ ₂	Type	Qty	
FWP-7575B	75	-0.1 -0.3	75	-0.1 -0.3	20	± 0.01	—	—	—	25	± 0.2	25	M10 Hexagon socket head	2	A
FWP-75100B	75	-0.1 -0.3	100	-0.1 -0.3	20	± 0.01	—	—	—	50	± 0.2	25	M10 Hexagon socket head	2	A
FWP-75125	75	-0.1 -0.3	125	-0.1 -0.3	20	± 0.01	—	—	—	75	± 0.2	25	M10 Hexagon socket head	2	A
FWP-75150	75	-0.1 -0.3	150	-0.1 -0.3	20	± 0.01	—	—	—	100	± 0.2	25	M10 Hexagon socket head	2	A
FWP-75200	75	-0.1 -0.3	200	-0.1 -0.3	20	± 0.01	—	—	—	150	± 0.2	25	M10 Hexagon socket head	2	A
FWP-100100	100	-0.1 -0.3	100	-0.1 -0.3	20	± 0.01	50	± 0.2	25	50	± 0.2	25	M10 Hexagon socket head	4	A
FWP-100125	100	-0.1 -0.3	125	-0.1 -0.3	20	± 0.01	50	± 0.2	25	75	± 0.2	25	M10 Hexagon socket head	4	A
FWP-100150	100	-0.1 -0.3	150	-0.1 -0.3	20	± 0.01	50	± 0.2	25	100	± 0.2	25	M10 Hexagon socket head	4	A
FWP-100200	100	-0.1 -0.3	200	-0.1 -0.3	20	± 0.01	50	± 0.2	25	150	± 0.2	25	M10 Hexagon socket head	4	A
FWP-100250	100	-0.1 -0.3	250	-0.1 -0.3	20	± 0.01	50	± 0.2	25	200	± 0.2	25	M10 Hexagon socket head	4	A
FWP-125125	125	-0.1 -0.3	125	-0.1 -0.3	20	± 0.01	75	± 0.2	25	75	± 0.2	25	M10 Hexagon socket head	4	A
FWP-125125A	125	-0.1 -0.3	125	-0.1 -0.3	20	± 0.01	50	± 0.2	37.5	75	± 0.2	25	M10 Hexagon socket head	4	A
FWP-125150	125	-0.1 -0.3	150	-0.1 -0.3	20	± 0.01	50	± 0.2	37.5	100	± 0.2	25	M10 Hexagon socket head	4	A
FWP-125200	125	-0.1 -0.3	200	-0.1 -0.3	20	± 0.01	50	± 0.2	37.5	150	± 0.2	25	M10 Hexagon socket head	4	A
FWP-125250	125	-0.1 -0.3	250	-0.1 -0.3	20	± 0.01	50	± 0.2	37.5	200	± 0.2	25	M10 Hexagon socket head	4	A
FWP-150150	150	-0.1 -0.3	150	-0.1 -0.3	20	± 0.01	100	± 0.2	25	100	± 0.2	25	M10 Hexagon socket head	4	A
FWP-150200	150	-0.1 -0.3	200	-0.1 -0.3	20	± 0.01	100	± 0.2	25	150	± 0.2	25	M10 Hexagon socket head	4	A
FWP-150250	150	-0.1 -0.3	250	-0.1 -0.3	20	± 0.01	100	± 0.2	25	200	± 0.2	25	M10 Hexagon socket head	4	A
FWP-200200	200	-0.1 -0.3	200	-0.1 -0.3	20	± 0.01	150	± 0.2	25	150	± 0.2	25	M10 Hexagon socket head	4	A
FWP-200250	200	-0.1 -0.3	250	-0.1 -0.3	20	± 0.01	150	± 0.2	25	200	± 0.2	25	M10 Hexagon socket head	4	A
FWP-200300	200	-0.1 -0.3	300	-0.1 -0.3	20	± 0.01	150	± 0.2	25	250	± 0.2	25	M10 Hexagon socket head	4	A