

■ PN geared type

Frame size [mm (in.)]	Model	Motor model	Driver model
□28 (1.10)	CRK523PAKD-N■	PK523PA-N■	CRD503-KD
□42 (1.65)	CRK544AKD-N■	PK544AW-N■	CRD507-KD
□60 (2.36)	CRK564AKD-N■	PK564AW-N■	CRD514-KD
	CRK566AKD-N■	PK566AW-N■	


■ Harmonic geared type

Frame size [mm (in.)]	Model	Motor model	Driver model
□20 (0.79)	CRK513PAKD-H■	PK513PA-H■S	CRD503-KD
□30 (1.18)	CRK523PAKD-H■	PK523HPA-H■S	CRD507H-KD
□42 (1.65)	CRK543AKD-H■	PK543AW-H■S	CRD507-KD
□60 (2.36)	CRK564AKD-H■	PK564AW-H■S	CRD514-KD

8-3 Names and functions of parts

■ Motor (Example: PK56)

● Standard type

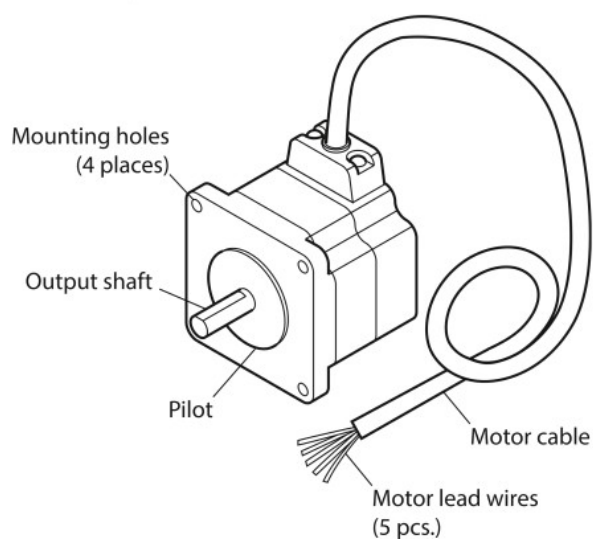

● Standard type with encoder

