


サニタリーフランジ (固定フランジ) / サニタリーフランジ (ルーズフランジ) / サニタリーフランジ (ラップジョイント)  
 Fixed Flange / Loose Flange / Lap joint

**サニタリーフランジ (固定フランジ) Fixed Flange**

Type VSF-T

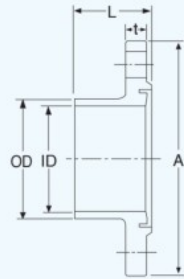

Nom.size	OD	ID	t	A	L	Mass kg	ボルト穴 Clearance Holes
1.0 <sup>S</sup>	25.4	23	9	78	40	0.30	4
1.5 <sup>S</sup>	38.1	35.7	9	92	40	0.40	4
2.0 <sup>S</sup>	50.8	47.8	11	110	40	0.66	4
2.5 <sup>S</sup>	63.5	59.5	11	125	40	0.86	4
3.0 <sup>S</sup>	76.3	72.3	12	140	50	1.16	6
3.5 <sup>S</sup>	89.1	85.1	12	150	50	1.24	6
4.0 <sup>S</sup>	101.6	97.6	12	165	50	1.46	6
4.5 <sup>S</sup>	114.3	108.3	13	180	50	1.92	8
5.5 <sup>S</sup>	139.8	133.8	13	205	50	2.28	8
6.5 <sup>S</sup>	165.2	159.2	13	230	50	2.62	8
200A	216.3	208.3	17	300	70	5.66	12

**サニタリーフランジ (ルーズフランジ) Loose Flange**

Type VSF-LS




\*すべて SUS304  
All SUS304

Nom.size	t	A	Mass kg	ボルト穴 Clearance Holes
1.0 <sup>S</sup>	12	78	0.32	4
1.5 <sup>S</sup>	12	92	0.42	4
2.0 <sup>S</sup>	14	110	0.68	4
2.5 <sup>S</sup>	14	125	0.80	4
3.0 <sup>S</sup>	16	140	1.04	6
3.5 <sup>S</sup>	16	150	1.10	6
4.0 <sup>S</sup>	16	165	1.26	6
4.5 <sup>S</sup>	18	180	1.62	8
5.5 <sup>S</sup>	18	205	1.90	8
6.5 <sup>S</sup>	18	230	2.18	8
200A	22	300	4.44	12

**サニタリーフランジ (ラップジョイント) Lap joint**

Type VSF-LP

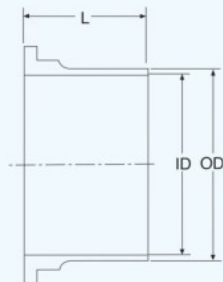

Nom.size	OD	ID	L	Mass kg
1.0 <sup>S</sup>	25.4	23	40	0.06
1.5 <sup>S</sup>	38.1	35.7	40	0.08
2.0 <sup>S</sup>	50.8	47.8	40	0.14
2.5 <sup>S</sup>	63.5	59.5	40	0.22
3.0 <sup>S</sup>	76.3	72.3	50	0.32
3.5 <sup>S</sup>	89.1	85.1	50	0.38
4.0 <sup>S</sup>	101.6	97.6	50	0.46
4.5 <sup>S</sup>	114.3	108.3	50	0.66
5.5 <sup>S</sup>	139.8	133.8	50	0.78
6.5 <sup>S</sup>	165.2	159.2	50	0.94
200A	216.3	208.3	70	2.06