


ヘルールホースアダプタ/ヘルール異径ホースアダプタ/ヘルールキャップ (Rcネジ付)
Hose Adapter end Ferrule/Reducing Hose Adapter ends Ferrule/Ferrule cap

ヘルールホースアダプタ Hose Adapter end Ferrule

Type HSAD-C


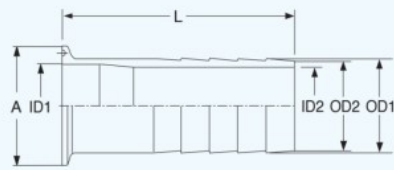


※SUS316Lのみ
Only SUS316L

Nom.size	OD1	OD2	ID1	ID2	A	L	Mass kg
1.0 ^S	25.4	23.7	23	21.4	50.5	85	0.14
1.25 ^S	31.8	30.1	29.4	27.8	50.5	90	0.15
1.5 ^S	38.1	36.4	35.7	34.1	50.5	100	0.18
2.0 ^S	50.8	49.1	47.8	44.8	64	125	0.36
2.5 ^S	63.5	61.8	59.5	57.5	77.5	140	0.56
3.0 ^S	76.3	74.6	72.3	70.3	91	160	0.78
3.5 ^S	89.1	87.4	85.1	82.1	106	160	1.07
4.0 ^S	101.6	99.9	97.6	94.6	119	170	1.28
※8A	13.8	12.8	10.5	10.5	34	42	0.050
※10A	17.3	16.3	14	14	34	42	0.050
※15A	21.7	20.7	17.5	17.5	34	42	0.060

ヘルール異径ホースアダプタ Reducing Hose Adapter ends Ferrule

Type HSAD-CX

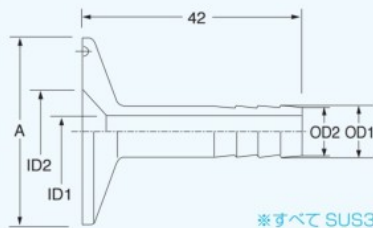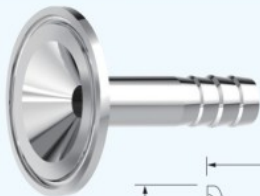


※すべて SUS316L
All SUS316L

Nom.size	OD1	OD2	ID1	ID2	A	Mass kg
1.0 ^S x 8A	13.8	12.8	10.5	23	50.5	0.098
1.0 ^S x 10A	17.3	16.3	14	23	50.5	0.099
1.0 ^S x 15A	21.7	20.7	17.5	23	50.5	0.107
1.5 ^S x 8A	13.8	12.8	10.5	35.7	50.5	0.083
1.5 ^S x 10A	17.3	16.3	14	35.7	50.5	0.086
1.5 ^S x 15A	21.7	20.7	17.5	35.7	50.5	0.096

ヘルールキャップ (Rc ネジ付) Ferrule cap (RC Screw)

Type CLF-BRC

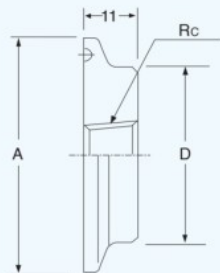

※すべて SUS316L
All SUS316L

Nom.size	A	D	Mass kg
15A x Rc 1/4	34	21.7	0.042
15A x Rc 3/8	34	21.7	0.035
1.5 ^S x Rc 1/4	50.5	38.1	0.119
1.5 ^S x Rc 3/8	50.5	38.1	0.112
1.5 ^S x Rc 1/2	50.5	38.1	0.101
1.5 ^S x Rc 3/4	50.5	38.1	0.082
1.5 ^S x Rc 1	50.5	38.1	0.054
2.0 ^S x Rc 1/4	64	50.8	0.189
2.0 ^S x Rc 3/8	64	50.8	0.182
2.0 ^S x Rc 1/2	64	50.8	0.171
2.0 ^S x Rc 3/4	64	50.8	0.152

Photo is 3DCG.