

## ③ サニタリー継手

## ISOヘルールユニオン継手

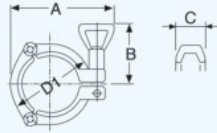
ISO Ferrule Union Fittings

3Kクランプ/3Kクランプ(脱落防止仕様)/2Kクランプ/2Dクランプ  
Clamp Type 3K/Clamp Type 3K(Dropout prevention)/Clamp Type 2K/Clamp Type 2D

## 3K クランプ

## Clamp Type 3K

## Type CP3K

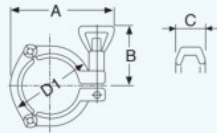
※1.0<sup>S</sup>~1.5<sup>S</sup> 共用

Nom.size	D1	A	B	C	Mass kg
※1.5 <sup>S</sup>	65.5	87.3	57	18	0.28
2.0 <sup>S</sup>	79	102	57	18	0.33
2.5 <sup>S</sup>	92.5	115.8	57	18	0.4
3.0 <sup>S</sup>	106	130.5	57	18	0.44
3.5 <sup>S</sup>	121	146	57	18	0.52
4.0 <sup>S</sup>	134	159.5	57	18	0.57
4.5 <sup>S</sup>	145	171	57	18	0.61
5.5 <sup>S</sup>	172	197.5	62	26	1
6.5 <sup>S</sup>	200	225.5	62	26	1.2
200A(8.5 <sup>S</sup> )	251	278	64	26	1.6

## 3K クランプ (脱落防止仕様)

## Clamp Type 3K(Dropout prevention)

## Type CP3KII

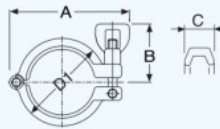
※1.0<sup>S</sup>~1.5<sup>S</sup> 共用

Nom.size	D1	A	B	C	Mass kg
※1.5 <sup>S</sup>	65.5	87.3	60	18	-
2.0 <sup>S</sup>	79	102	60	18	-
2.5 <sup>S</sup>	92.5	115.8	60	18	-
3.0 <sup>S</sup>	106	130.5	60	18	-
3.5 <sup>S</sup>	121	146	60	18	-
4.0 <sup>S</sup>	134	159.5	60	18	-
4.5 <sup>S</sup>	145	171	60	18	-

## 2K クランプ

## Clamp Type 2K

## Type CP2K

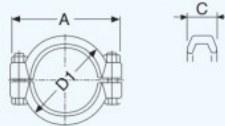
※8A~15A 共用 ※1.0<sup>S</sup>~1.5<sup>S</sup> 共用

Nom.size	D1	A	B	C	Mass kg
※1.5 <sup>S</sup>	64	92	51.5	16	0.23
2.0 <sup>S</sup>	77.5	105.8	51.5	16	0.22
2.5 <sup>S</sup>	91	119.5	51.5	16	0.25
3.0 <sup>S</sup>	105	134	51.5	16	0.29
3.5 <sup>S</sup>	120.5	149.5	52.5	17	0.383
4.0 <sup>S</sup>	133.5	163	52.5	17	0.417
※15A	46	72.5	50	16	0.16

## 2D クランプ

## Clamp Type 2D

## Type CP2D

※8A~15A 共用 ※1.0<sup>S</sup>~1.5<sup>S</sup> 共用

Nom.size	D1	A	C	Mass kg
※1.5 <sup>S</sup>	63	86	16	0.22
2.0 <sup>S</sup>	76.5	100	16	0.25
2.5 <sup>S</sup>	90	115	16	0.29
3.0 <sup>S</sup>	103.5	130	16	0.33
3.5 <sup>S</sup>	119	144	17	0.4
4.0 <sup>S</sup>	132	158	17	0.46
4.5 <sup>S</sup>	143	172	17	0.49
5.5 <sup>S</sup>	174	208	25	1.2
6.5 <sup>S</sup>	202	238	25	1.3
200A(8.5 <sup>S</sup> )	253	288	25	1.6
※15A	46	64	16	0.13

写真は3DCGです。Photo is 3DCG.