


# 高送りラジアスカッタ

High Feed Radius Cutter

## PHC インサート

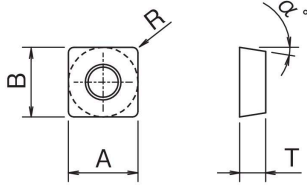

■適用インサート Applicable Inserts

(単位:mm) (Unit:mm)

形状 Appearance	呼び Designation	切れ刃数 No. of Cutting Edges	インサート寸法 Insert Size					コーティング材種 Grade of Coated Materials					標準価格 (Yen)
			A×B	厚さ T	逃げ角 α°	R	さらい刃 (副切れ刃) b	XP3035	XP2040	XC1015	XC5035	XC5040	
①	SDMT09T308SR-GM	4	9.52×9.52	3.97	15	0.8	1.9	7814020	7813020	7812020			1,180
	SDMT09T308ER-SM	4	9.52×9.52	3.97	15	0.8	1.9				7815021	7816021	2,140
②	SXMT120410SR-GM	4	12.7×12.7	4.76	9	1	1.3	7814022	7813022	7812022			1,370
	SXMT120410ER-SM	4	12.7×12.7	4.76	9	1	1.3				7815023	7816023	2,510

在庫区分はすべてC (標準在庫品) となります。 Stocks are categorized as C (standard stock item).

■部品 Accessories

	ツールNo. EDP No.	在庫 Stock	呼び Designation	適用インサート Applicable Inserts	適用カッタ Applicable Cutters
 クランプねじ Clamping Screw	7808111	C	FS35572 (Torx 15)	① SDMT09...	PHC SS/SF φ 25 ~ 35
	7808112	C	FS35586 (Torx 15)		PHC SS/SF φ 40 PHC BORE φ 40 ~ 63
	7808113	C	FS45510 (Torx 20)	② SXMT12...	PHC SS/SF φ 30 ~ 63 PHC BORE φ 40 ~ 100
 パワースクリュー Power Screw	7808150	C	PS0830 (M8×30)	① SDMT09...	PHC BORE φ 40
				② SXMT12...	

	ツールNo. EDP No.	在庫 Stock	呼び Designation	適用インサート Applicable Inserts	適用カッタ Applicable Cutters	標準価格 (Yen)
 レンチ Wrench	7808208	C	T15-D (Torx 15)	① SDMT09...	PHC SS/SF φ 25 ~ 40 PHC BORE φ 40 ~ 63	1,040
	7808209	C	T20-D (Torx 20)	② SXMT12...	PHC SS/SF φ 30 ~ 63 PHC BORE φ 40 ~ 100	1,040

レンチは別途ご購入下さい。 The wrenches are sold separately from the cutters.