


仕上げ用ボールエンドミル

Finishing Ball End Mill

PFB NEW SIZES

●マークの説明はP1をご覧ください。
See page 1 for explanation of icons.

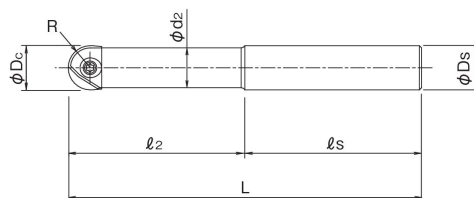

P.664

**■超硬シャンク ショートタイプ** Carbide Shank, Short Type

(単位:mm) (Unit:mm)

ツール No. EDP No.	呼び Designation	外径 Dc	ボール 半径 R	全長 L	有効長		刃数 z	シャン径 Ds	シャン長 ℓs	首径 d2	在庫 Stock	標準価格 (Yen)
					首下長 ℓ2	L/D						
NEW 7801429	PFB-R060SS06-S80CS*	6	3	80	15	2.5	2	6	65	5.4	C	31,100
7801430	PFB-R080SS08-S100CS	8	4	100	20	2.5	2	8	80	7	C	32,600
7801431	PFB-R100SS10-S100CS	10	5	100	25	2.5	2	10	75	9	C	33,100
7801432	PFB-R120SS12-S110CS	12	6	110	30	2.5	2	12	80	11	C	38,800
7801433	PFB-R160SS16-S140CS	16	8	140	40	2.5	2	16	100	14	C	46,300
7801434	PFB-R200SS20-S160CS	20	10	160	50	2.5	2	20	110	18	C	65,900
7801435	PFB-R250SS25-S160CS	25	12.5	160	62.5	2.5	2	25	97.5	22	C	85,600
7801436	PFB-R300SS32-S170CS	30	15	170	75	2.5	2	32	95	27	C	109,000
NEW 7801437	PFB-R320SS32-S180CS	32	16	180	80	2.5	2	32	100	29	C	115,000

*PFB070-Qを取付け可能 *PFB070-Q can be attached

■超硬シャンク ロングタイプ **NEW** Carbide Shank, Long Type

(単位:mm) (Unit:mm)

ツール No. EDP No.	呼び Designation	外径 Dc	ボール 半径 R	全長 L	有効長		刃数 z	シャン径 Ds	シャン長 ℓs	首径 d2	在庫 Stock	標準価格 (Yen)
					首下長 ℓ2	L/D						
7801439	PFB-R060SS06-L100CS*	6	3	100	30	5	2	6	70	5.4	C	33,800
7801440	PFB-R080SS08-L120CS	8	4	120	40	5	2	8	80	7	C	35,300
7801441	PFB-R100SS10-L130CS	10	5	130	50	5	2	10	80	9	C	35,800
7801442	PFB-R120SS12-L140CS	12	6	140	60	5	2	12	80	11	C	41,800
7801443	PFB-R160SS16-L160CS	16	8	160	72	4.5	2	16	88	14	C	49,700
7801444	PFB-R200SS20-L180CS	20	10	180	90	4.5	2	20	90	18	C	73,300
7801445	PFB-R250SS25-L200CS	25	12.5	200	100	4	2	25	100	22	C	95,500
7801446	PFB-R300SS32-L220CS	30	15	220	120	4	2	32	100	27	C	129,000
7801447	PFB-R320SS32-L230CS	32	16	230	128	4	2	32	102	29	C	136,000

*PFB070-Qを取付け可能 *PFB070-Q can be attached

■超硬シャンク エキストラロングタイプ Carbide Shank, Extra Long Type

(単位:mm) (Unit:mm)

ツール No. EDP No.	呼び Designation	外径 Dc	ボール 半径 R	全長 L	有効長		刃数 z	シャン径 Ds	シャン長 ℓs	首径 d2	在庫 Stock	標準価格 (Yen)
					首下長 ℓ2	L/D						
NEW 7801419	PFB-R060SS06-LL120CS*	6	3	120	42	7	2	6	78	5.4	C	35,600
7801420	PFB-R080SS08-LL140CS	8	4	140	56	7	2	8	84	7	C	37,200
7801421	PFB-R100SS10-LL150CS	10	5	150	70	7	2	10	80	9	C	37,700
7801422	PFB-R120SS12-LL160CS	12	6	160	84	7	2	12	76	11	C	47,300
7801423	PFB-R160SS16-LL200CS	16	8	200	96	6	2	16	104	14	C	52,400
7801424	PFB-R200SS20-LL240CS	20	10	240	120	6	2	20	120	18	C	78,900
7801425	PFB-R250SS25-LL260CS	25	12.5	260	137.5	5.5	2	25	122.5	22	C	113,000
7801426	PFB-R300SS32-LL290CS	30	15	290	165	5.5	2	32	125	27	C	161,000
NEW 7801427	PFB-R320SS32-LL300CS	32	16	300	176	5.5	2	32	124	29	C	168,000

*PFB070-Qを取付け可能 *PFB070-Q can be attached