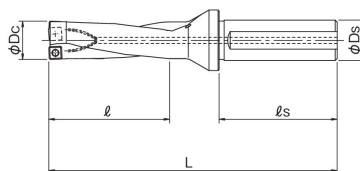
 


インデキサブルドリル

Indexable Drill

PHP

油穴付き
With coolant hole●マークの説明はP1をご覧ください。
See page 1 for explanation of icons.

P.676

■形状寸法表 Specification Chart

(単位:mm) (Unit:mm)

ツール No. EDP No.	呼び Designation	外径 D_c	全長 L	溝長 ℓ	シャンク径 D_s	シャンク長 ℓ_s	適用チップ Applicable Inserts	在庫 Stock	標準価格 (Yen)
7800100	PHP140FS20M04-3D	14	116	42	20	50	①	C	64,800
7800101	PHP145FS20M04-3D	14.5	119	45	20	50		C	64,800
7800102	PHP150FS20M04-3D	15	119	45	20	50		C	64,800
7800103	PHP155FS20M04-3D	15.5	122	48	20	50		C	64,800
7800104	PHP160FS20M04-3D	16	122	48	20	50		C	64,800
7800105	PHP165FS20M05-3D	16.5	125	51	20	50	②	C	64,800
7800106	PHP170FS20M05-3D	17	125	51	20	50		C	64,800
7800107	PHP175FS25M05-3D	17.5	134	54	25	56		C	64,800
7800108	PHP180FS25M05-3D	18	134	54	25	56		C	65,500
7800109	PHP185FS25M06-3D	18.5	137	57	25	56		C	65,500
7800110	PHP190FS25M06-3D	19	137	57	25	56	③	C	65,500
7800111	PHP195FS25M06-3D	19.5	140	60	25	56		C	65,500
7800112	PHP200FS25M06-3D	20	140	60	25	56		C	65,500
7800113	PHP205FS25M06-3D	20.5	143	63	25	56		C	65,500
7800114	PHP210FS25M07-3D	21	143	63	25	56		C	65,500
7800115	PHP215FS25M07-3D	21.5	146	66	25	56	④	C	65,500
7800116	PHP220FS25M07-3D	22	146	66	25	56		C	68,400
7800117	PHP225FS25M07-3D	22.5	149	69	25	56		C	68,400
7800118	PHP230FS25M07-3D	23	149	69	25	56		C	68,400
7800119	PHP235FS32M07-3D	23.5	156	72	32	60		C	68,400
7800120	PHP240FS32M07-3D	24	156	72	32	60	⑤	C	68,400
7800121	PHP245FS32M08-3D	24.5	159	75	32	60		C	68,400
7800122	PHP250FS32M08-3D	25	159	75	32	60		C	68,400
7800123	PHP255FS32M08-3D	25.5	162	78	32	60		C	68,400
7800124	PHP260FS32M08-3D	26	162	78	32	60		C	68,400
7800125	PHP265FS32M08-3D	26.5	165	81	32	60	⑥	C	68,400
7800126	PHP270FS32M08-3D	27	165	81	32	60		C	68,400
7800127	PHP280FS32M08-3D	28	168	84	32	60		C	76,600
7800128	PHP290FS32M10-3D	29	171	87	32	60		C	76,600
7800129	PHP300FS32M10-3D	30	179	90	32	60		C	76,600
7800130	PHP310FS32M10-3D	31	182	93	32	60	⑦	C	76,600
7800131	PHP320FS32M10-3D	32	185	96	32	60		C	76,600
7800132	PHP330FS40M10-3D	33	196	99	40	68		C	76,600
7800133	PHP340FS40M10-3D	34	199	102	40	68		C	98,200
7800134	PHP350FS40M12-3D	35	202	105	40	68		C	98,200
7800135	PHP360FS40M12-3D	36	205	108	40	68	⑦	C	98,200
7800136	PHP370FS40M12-3D	37	218	111	40	68		C	98,200
7800137	PHP380FS40M12-3D	38	221	114	40	68		C	98,200
7800138	PHP390FS40M12-3D	39	224	117	40	68		C	98,200
7800139	PHP400FS40M12-3D	40	227	120	40	68		C	98,200