


Replaceable Contact Points (M1.7 × 0.35)

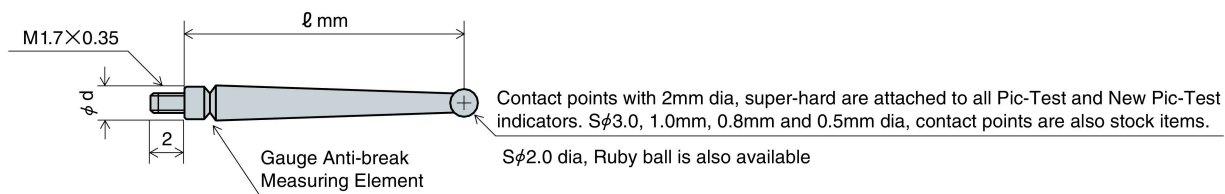

For Pic Test (Change lever type)

Part No.	ℓ (mm)	φ ball (mm)	φ d (mm)	Applicable Indicator
XP1A-3	18.2	3	2.5	PC-1A PC-1AE PC-3
XP1A-2	18.2	2	2.5	PC-1A PC-1AE PC-3
XP1A-2R (ruby ball)	18.2	2	2.5	PC-1A PC-1AE PC-3
XP1A-1	18.2	1	2.5	PC-1A PC-1AE PC-3
XP1A-08	18.2	0.8	2.5	PC-1A PC-1AE PC-3
XP1A-05	18.2	0.5	2.5	PC-1A PC-1AE PC-3
XP1B-3	19.24	3	2.5	PC-1B PC-1BE PC-1BW
XP1B-2	19.24	2	2.5	PC-1B PC-1BE PC-1BW
XP1B-2R (ruby ball)	19.24	2	2.5	PC-1B PC-1BE PC-1BW
XP1B-1	19.24	1	2.5	PC-1B PC-1BE PC-1BW
XP1B-08	19.24	0.8	2.5	PC-1B PC-1BE PC-1BW
XP1B-05	19.24	0.5	2.5	PC-1B PC-1BE PC-1BW
XP1L-3	39.72	3	3.0	PC-1L PC-1LE PC-3L
XP1L-2	39.72	2	3.0	PC-1L PC-1LE PC-3L
XP1L-2R (ruby ball)	39.72	2	3.0	PC-1L PC-1LE PC-3L
XP1L-1	39.72	1	3.0	PC-1L PC-1LE PC-3L
XP1L-08	39.72	0.8	3.0	PC-1L PC-1LE PC-3L
XP1L-05	39.72	0.5	3.0	PC-1L PC-1LE PC-3L
XP2-3	8.80	3	2.2	PC-2 PC-4
XP2-2	8.80	2	2.2	PC-2 PC-4
XP2-2R (ruby ball)	8.80	2	2.2	PC-2 PC-4
XP2-1	8.80	1	2.2	PC-2 PC-4
XP2-08	8.80	0.8	2.2	PC-2 PC-4
XP2-05	8.80	0.5	2.2	PC-2 PC-4

For New Pic Test (without Change lever type)

Part No.	ℓ (mm)	φ ball (mm)	φ d (mm)	Applicable Indicator
XN1A-3	17.74	3	2.5	PCN-1A PCN-0 PCN-1AE PCN-1AD PCN-5 PCN-7A
XN1A-2	17.74	2	2.5	PCN-1A PCN-0 PCN-1AE PCN-1AD PCN-5 PCN-7A
XN1A-2R (ruby ball)	17.74	2	2.5	PCN-1A PCN-0 PCN-1AE PCN-1AD PCN-5 PCN-7A PCN-1AU PCN-5U
XN1A-1	17.74	1	2.5	PCN-1A PCN-0 PCN-1AE PCN-1AD PCN-5 PCN-7A
XN1A-08	17.74	0.8	2.5	PCN-1A PCN-0 PCN-1AE PCN-1AD PCN-5 PCN-7A
XN1A-05	17.74	0.5	2.5	PCN-1A PCN-0 PCN-1AE PCN-1AD PCN-5 PCN-7A
XN1B-3	18.63	3	2.5	PCN-1B PCN-1BE PCN-1BZ (A)-(B)
XN1B-2	18.63	2	2.5	PCN-1B PCN-1BE PCN-1BZ (A)-(B)
XN1B-2R (ruby ball)	18.63	2	2.5	PCN-1B PCN-1BE PCN-1BU PCN-1BZ (A)-(B)
XN1B-1	18.63	1	2.5	PCN-1B PCN-1BE PCN-1BZ (A)-(B)
XN1B-08	18.63	0.8	2.5	PCN-1B PCN-1BE PCN-1BZ (A)-(B)
XN1B-05	18.63	0.5	2.5	PCN-1B PCN-1BE PCN-1BZ (A)-(B)
XN1L-3	39.00	3	2.5	PCN-1L PCN-1LE PCN-1LD PCN-1LZ (A)-(B)
XN1L-2	39.00	2	2.5	PCN-1L PCN-1LE PCN-1LD PCN-1LZ (A)-(B)
XN1L-2R (ruby ball)	39.00	2	2.5	PCN-1L PCN-1LE PCN-1LD PCN-1LU PCN-1LZ (A)-(B)
XN1L-1	39.00	1	2.5	PCN-1L PCN-1LE PCN-1LD PCN-1LZ (A)-(B)
XN1L-08	39.00	0.8	2.5	PCN-1L PCN-1LE PCN-1LD PCN-1LZ (A)-(B)
XN1L-05	39.00	0.5	2.5	PCN-1L PCN-1LE PCN-1LD PCN-1LZ (A)-(B)
XN2-3	14.33	3	2.2	PCN-2 PCN-2E PCN-6 PCN-2Z (A)-(B)
XN2-2	14.33	2	2.2	PCN-2 PCN-2E PCN-6 PCN-2Z (A)-(B)
XN2-2R (ruby ball)	14.33	2	2.2	PCN-2 PCN-2E PCN-6 PCN-2U PCN-6U PCN-2Z (A)-(B)
XN2-1	14.33	1	2.2	PCN-2 PCN-2E PCN-6 PCN-2Z (A)-(B)
XN2-08	14.33	0.8	2.2	PCN-2 PCN-2E PCN-6 PCN-2Z (A)-(B)
XN2-05	14.33	0.5	2.2	PCN-2 PCN-2E PCN-6 PCN-2Z (A)-(B)
XN2B-3	13.00	3	2.2	PCN-2B PCN-2BD PCN-7C PCN-SD
XN2B-2	13.00	2	2.2	PCN-2B PCN-2BD PCN-7C PCN-SD
XN2B-2R (ruby ball)	13.00	2	2.2	PCN-2B PCN-2BD PCN-7C PCN-SD PCN-2BU
XN2B-1	13.00	1	2.2	PCN-2B PCN-2BD PCN-7C PCN-SD
XN2B-08	13.00	0.8	2.2	PCN-2B PCN-2BD PCN-7C PCN-SD
XN2B-05	13.00	0.5	2.2	PCN-2B PCN-2BD PCN-7C PCN-SD
XNS-3	8.13	3	2.2	PCN-S
XNS-2	8.13	2	2.2	PCN-S
XNS-2R (ruby ball)	8.13	2	2.2	PCN-S PCN-SU
XNS-1	8.13	1	2.2	PCN-S
XNS-08	8.13	0.8	2.2	PCN-S
XNS-05	8.13	0.5	2.2	PCN-S