

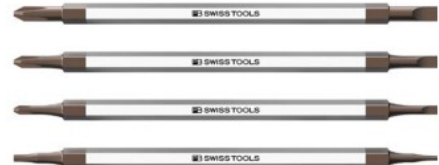
PB 52








Interchangeable blade for Insider Mini PB 169

- for slotted, Phillips and for Pentalobe®-screws
- precise, true-to-size tips, optimal fit in the screw heads
- special alloy based on spring steel, exceptional elasticity coupled with high grade hardening
- laser-marked serial number, lifetime guarantee

Hoja intercambiable para Insider Mini PB 169

- para tornillos de ranura, Phillips y Pentalobe®
- punta precisa de dimensiones exactas, ajuste óptimo en los tornillos
- aleación especial de acero para resortes, elasticidad extraordinaria y gran dureza
- rotulación láser con n.º de serie, garantía de por vida



							
PB 52CPH.000-70	000	000	-	70	3	10	7 610733 265794
PB 52CPH.00-70	00	00	-	70	3	10	7 610733 265800
PB 52CPH.0-70	0	0	-	70	3	10	7 610733 265817
PB 52PN.0,8-1,2-70	-	-	0,8+1,2	70	3	10	7 610733 265824

PB 215 C








Interchangeable blade for PB 215 A, 8215 A, DigiTorque and MecaTorque handles

- for slotted screws
- parallel tip, optimum transmission of force, no cam-out
- special alloy based on spring steel, exceptional elasticity coupled with high grade hardening
- laser-marked serial number, lifetime guarantee

Hoja intercambiable para mangos PB 215 A, 8215 A, DigiTorque y MecaTorque

- para tornillos de ranura
- puntas paralelas, óptima transmisión de fuerza, sin efecto de expulsión
- aleación especial de acero para resortes, elasticidad extraordinaria y gran dureza
- rotulación láser con n.º de serie, garantía de por vida



								
PB 215.C 2	2.5	4	0.6	90	170	28	10	7 610733 014750
PB 215.C 3	3	5.5	0.8	100	180	33	10	7 610733 014767
PB 215.C 4	3.5	6.5	1	110	190	39	10	7 610733 014774
PB 215.C 5	4-5	8	1.2	120	200	42	10	7 610733 014781