

**PB 2212 H**

**Key L-wrenches with ball point and short 100° key part, set in practical plastic holder**

- for hexagon socket screws
- short key part with 100° angle, no more inaccessible screws
- perfectly shaped ball point, allows screws to be turned at an angle of up to 30°
- special alloy based on spring steel, exceptional elasticity coupled with high grade hardening
- laser-marked serial number, lifetime guarantee

**Llaves acodadas con cabeza esférica y parte insertable corta en 100°; juego en práctico soporte de plástico**

- para tornillos con hexágono interior
- parte insertable corta con ángulo de 100°; se acabaron los tornillos inaccesibles
- cabeza esférica de forma perfecta, que permite girar tornillos con un ángulo de hasta 30°
- aleación especial de acero para resortes, elasticidad extraordinaria y gran dureza
- rotulación láser con n.º de serie, garantía de por vida



PB 2212.H-10	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10	236	10	7 610733 207886	

**In blister packs  
En embalaje blíster**



PB 2212.H-10 CN	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10	255	10	7 610733 236466	


**PB 2212 LH**

**Key L-wrenches long, with ball point and short key part and 100° angle, set in a practical plastic holder**

- for hexagon socket screws
- short key part with 100° angle, no more inaccessible screws
- perfectly shaped ball point, allows screws to be turned at an angle of up to 30°
- special alloy based on spring steel, exceptional elasticity coupled with high grade hardening
- laser-marked serial number, lifetime guarantee

**Llaves acodadas largas; cabeza esférica y parte insertable corta en 100°; juego en práctico sop. de plástico**

- para tornillos con hexágono interior
- parte insertable corta con ángulo de 100°; se acabaron los tornillos inaccesibles
- cabeza esférica de forma perfecta, que permite girar tornillos con un ángulo de hasta 30°
- aleación especial de acero para resortes, elasticidad extraordinaria y gran dureza
- rotulación láser con n.º de serie, garantía de por vida

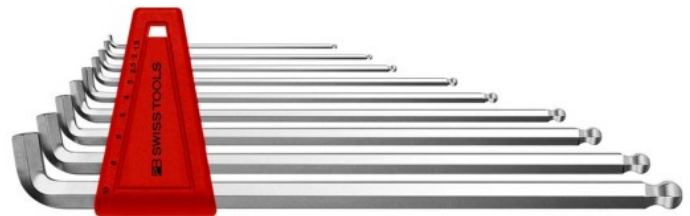

PB 2212.LH-10	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10	377	10	7 610733 203680	

**In blister packs  
En embalaje blíster**



PB 2212.LH-10 CN	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10	412	10	7 610733 236459	