


15 series Socket

**CPS15** Straight Tube Socket

CAD

RoHS compliant

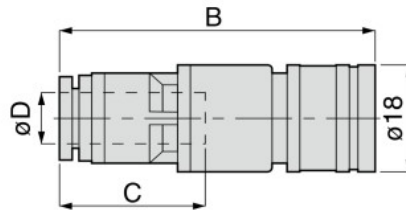


Unit : mm

| Model code | Tube O.D. $\phi D$ | B    | Tube end C | Weight (g) | Effective area (mm <sup>2</sup> ) | CAD file name |
|------------|--------------------|------|------------|------------|-----------------------------------|---------------|
| CPS15-6 □  | 6                  | 49.8 | 16.8       | 13         | 11                                | TFLC-003      |
| CPS15-8 □  | 8                  | 50.7 | 18.1       | 14         | 18                                |               |
| CPS15-10 □ | 10                 | 54   | 20.2       | 17         | 18                                |               |

**CPS15** Straight Screw Socket

CAD

RoHS compliant

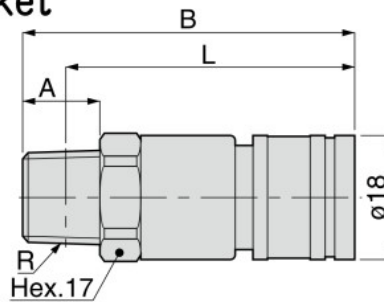

Unit : mm


| Model code | R    | A  | B  | L    | Weight (g) | Effective area (mm <sup>2</sup> ) | CAD file name |
|------------|------|----|----|------|------------|-----------------------------------|---------------|
| CPS15-01 □ | R1/8 | 8  | 44 | 40   | 26         | 18                                | TFLC-003      |
| CPS15-02 □ | R1/4 | 11 | 47 | 41   | 30         |                                   |               |
| CPS15-03 □ | R3/8 | 12 | 48 | 41.7 | 38         |                                   |               |

※ . "L" is a reference value for height dimension after tightening thread.

**CPS15** Bulkhead Tube Socket

CAD

RoHS compliant

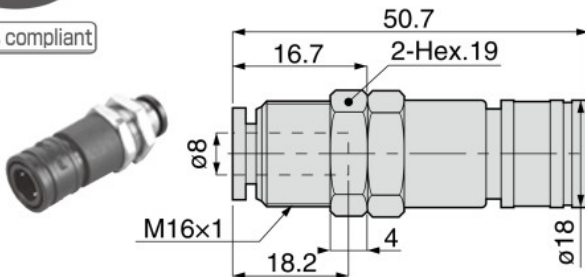

| Model code | Weight (g) | Effective area (mm <sup>2</sup> ) | CAD file name |
|------------|------------|-----------------------------------|---------------|
| CPS15M-8 □ | 36         | 18                                | TFLC-003      |