


Model Designation (Example)

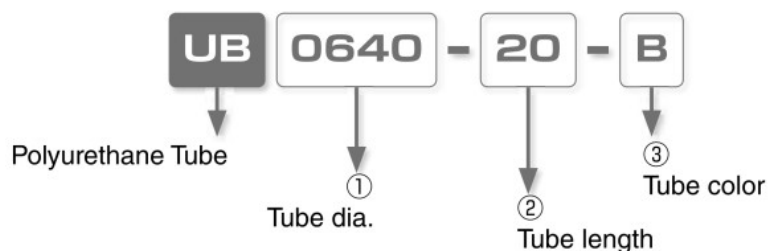

① Tube dia. (O.D. x I.D.)

mm size

Code	01810	0320	0425(5/32)	0640	0850(5/16)	1065	1280	1611(5/8)
O.D. (mm)	ø1.8	ø3	ø4	ø6	ø8	ø10	ø12	ø16
I.D. (mm)	ø1	ø2	ø2.5	ø4	ø5	ø6.5	ø8	ø11

inch size

Code	1/8	3/16	1/4	3/8	1/2
O.D. (mm)	ø3.18	ø4.76	ø6.35	ø9.53	ø12.7
I.D. (mm)	ø2	ø2.99	ø4.15	ø5.99	ø8.5

② Tube length

Code	20	50	100
Length(m)	20	50	100

※ 50m is available for Tube dia. of mm size only.

※ UB1810 and UB1611 are available only with 20m length.

③ Tube color

Code	B	R	O	YB	Y	G	Bu	CB	C	W
Color	Black	Red	Orange	Ocher	Yellow	Green	Blue	Clear blue	Transparent	Milky white

※ Standard color for inch size 1/8, 3/16, 1/4, 3/8 and 1/2 are only Black and Orange.

※ Only Black color is available for 50meters length Tube.

Make-to-order product

Tube diameter / Length list

Model code		Reel (m/reel)	Bundle (small) (m/bundle)	Bundle (large) ※ 2 (m/bundle)
mm size	inch size			
UB0320	UB1/8	300	300	—
UB0425	UB5/32, UB3/16	300	300	—
UB0640	UB1/4	300	300	—
UB0850	UB5/16	200	200	500
UB1065	UB3/8	150	150	300
UB1280	UB1/2	100	100	200
UB1611	UB5/8	50	50	100

※ 1. MOQ of make-to-order tube is 500m.

※ 2. Bundle (large) is packed on a pallet. Contact the nearest sales office for the freight charge.