


Model Designation (Example)

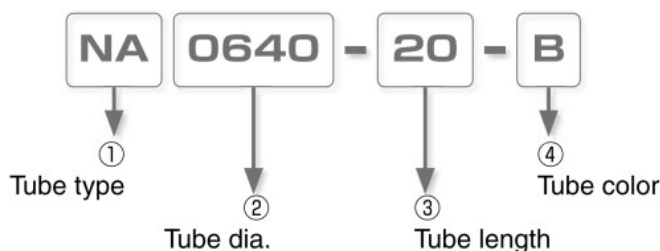

① Tube type

NA : Nylon Tube
 NB : Soft Nylon Tube

② Tube dia. (O.D. x I.D.)

Code	mm size						inch size				
	0425(5/32)	0640	0860(5/16)	1075	1290	1613(5/8)	1/8	3/16	1/4	3/8	1/2
O.D. (mm)	ø4	ø6	ø8	ø10	ø12	ø16	ø3.18	ø4.76	ø6.35	ø9.53	ø12.7
I.D. (mm)	ø2.5	ø4	ø6	ø7.5	ø9	ø13	ø2	ø2.99	ø4.57	ø6.99	ø9.56

※ There is no inch size selection for NB Tube as a standard item.

③ Tube length

Code	20	100
Length(m)	20	100

※ NA1613 (5/8) and NB1613 are available only with 20m length.

④ Tube color

code	B	R	O	YB	Y	G	Bu	CB	W	BR	YG	P
Color	Black	Red	Orange	Ocher	Yellow	Green	Blue	Clear blue	Milky white	Brown	Yellow green	Pink
N A	mm size	○	○	○	○	○	○	○	○			
	inch size	○							○			
NB	○	○	△	△	○	△	○	○	○	△	△	△

※ Standard colors for inch sized NA Tube 1/8, 3/16, 1/4, 3/8 and 1/2 are Black and Milky white.

※ Standard colors for NB1613 are Black, Blue and Milky white. Other colors are available as a make-to-order product.

※ Color selection with marking △ is available as a make-to-order product. MOQ is 500m.

Make-to-order product

Tube diameter / Length list

Model code		Reel (m / reel)	Bundle (small) (m / reel)	Bundle (large) ※ 2 (m / reel)
mm size	inch size			
NA0425, NB0425	NA1/8, NA5/32, NA3/16	500	500	—
NA0640, NB0640	NA1/4	500	500	—
NA0860, NB0860	NA5/16	200	200	500
NA1075, NB1075	NA3/8	150	150	300
NA1290, NB1290	NA1/2	100	100	300
NA1613, NB1613	NA5/8	50	50	200

※ 1. MOQ of make-to-order tube is 500m.

※ 2. Bundle (large) is packed on a pallet. Contact the nearest sales office for the freight charge.