


■ Connection : Tube ⇄ Tube

JNMU Small union straight



RoHS compliant

Renewal

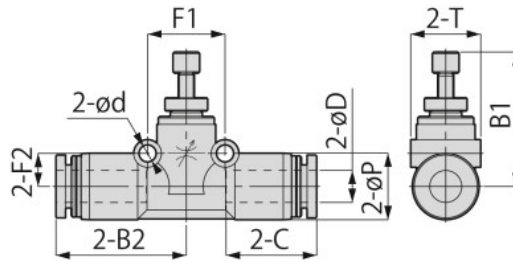

Unit : mm

Model code	Tube O.D. øD	B1		B2	øP	T	Tube end C	ød	F1	F2	Weight (g)	CAD File name
		max.	min.									
JNMU4□	4	20.5	18.1	21	10	10.5	14.9	3.2	12.7	4.8	8.9	JNMU4_
JNMU6□	6	25.4	21.6	24.4	12.5	13.1	17	3.2	14.8	6.2	14	JNMU6_
JNMU8□	8	28.3	24.6	28	14.8	15.4	18.1	3.2	18.2	7.2	25	JNMU8_
JNMU10□	10	32.8	28.9	31.8	18.2	19.7	20.2	4.2	22.2	8.7	45	JNMU10_
JNMU12□	12	35.4	31.5	36.9	21.2	22.7	23.4	4.2	25.7	10.2	65	JNMU12_
JNMU5/32□	5/32	20.5	18.1	21	10	10.5	14.9	3.2	12.7	4.8	8.9	JNMU5_32_
JNMU1/4□	1/4	25.4	21.6	24.4	12.5	13.1	17	3.2	14.8	6.2	14	JNMU1_4_
JNMU5/16□	5/16	28.3	24.6	28	14.8	15.4	18.1	3.2	18.2	7.2	25	JNMU5_16_
JNMU3/8□	3/8	32.8	28.9	31.8	18.2	19.7	20.2	4.2	22.2	8.7	45	JNMU3_8_
JNMU1/2□	1/2	35.4	31.5	37.2	21.2	22.7	23.7	4.2	25.7	10.2	65	JNMU1_2_

※. □ in Model code / No entry for Black color. Or replaced with color or packaging option code below.

Color : Light-gray ⇒ Code : W、Packaging : Clean-room package ⇒ Code : -C、

Color : Light-gray & Packaging : Clean-room package ⇒ Code : W-C