

Tube Series


Coiling Tube Series

UL Polyurethane Coiling Tube

RoHS compliant

NL Nylon Coiling Tube

RoHS compliant

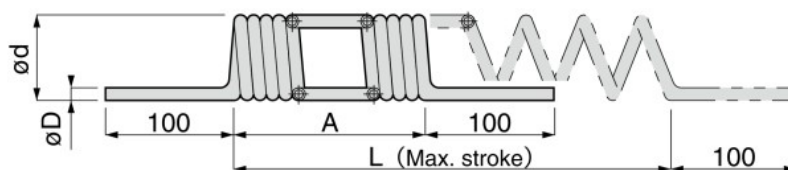

Unit : mm

Unit : mm

Model code	Tube O.D. x I.D. øD	L	A	ød
UL 03-1-□	3 × 2	210	70	16
UL 03-2-□		450	150	
UL 03-3-□		700	230	
UL 03-5-□		1200	390	
UL 04-2-□	4 × 2.5	360	120	24
UL 04-3-□		540	180	
UL 04-5-□		1100	350	
UL 04-7-□		1500	480	
UL 04-10-□		2100	700	
UL 04-14-□		3200	1040	
UL 04-20-□		4400	1450	
UL 06-2-□	6 × 4	500	160	30
UL 06-3-□		700	230	
UL 06-5-□		1300	430	
UL 06-7-□		1900	620	
UL 06-10-□		2800	910	
UL 06-14-□		3900	1300	
UL 06-20-□		5600	1850	
UL 08-3-□	8 × 5	750	250	42
UL 08-5-□		1200	390	
UL 08-7-□		1700	540	
UL 08-10-□		2400	770	
UL 08-14-□		3200	1045	
UL 08-20-□	8 × 5	4700	1550	42
UL 10-5-□		1000	330	
UL 10-7-□		1400	470	
UL 10-10-□		2100	680	
UL 10-14-□	10 × 6.5	3000	970	58
UL 10-20-□		4200	1380	
UL 12-5-□	12 × 8	1000	310	72
UL 12-7-□		1400	450	
UL 12-10-□		2000	660	
UL 12-14-□		2800	920	
UL 12-20-□		4000	1320	

※ . □ in model code : Replaced with Tube color code

Model code	Tube O.D. x I.D. øD	L	A	ød
NL 04-2-□	4 × 2.5	300	100	27
NL 04-3-□		500	165	
NL 04-5-□		900	280	
NL 04-7-□		1200	395	
NL 04-10-□		1800	580	
NL 04-14-□		2500	820	
NL 04-20-□	6 × 4	3600	1200	35
NL 06-2-□		420	140	
NL 06-3-□		650	210	
NL 06-5-□		1100	340	
NL 06-7-□		1500	480	
NL 06-10-□		2100	680	
NL 06-14-□	8 × 6	2900	960	62
NL 06-20-□		4200	1400	
NL 08-3-□		420	140	
NL 08-5-□		700	230	
NL 08-7-□		1000	330	
NL 08-10-□		1500	500	
NL 08-14-□	10 × 7.5	2100	700	85
NL 08-20-□		3000	1000	
NL 10-5-□		660	220	
NL 10-7-□		1000	325	
NL 10-10-□	12 × 9	1400	460	114
NL 10-14-□		2000	650	
NL 10-20-□		2800	930	
NL 12-5-□		600	200	
NL 12-7-□		900	280	
NL 12-10-□	12 × 9	1300	410	114
NL 12-14-□		1800	590	
NL 12-20-□		2500	820	

※ . □ in model code : Replaced with Tube color code

623

Standard
Tube

Multi-core
Tube

Coiling
Tube

TUBE
VALVE
CONTROLLER
FITTING