

Rotating Signal Tower

# KES/KESB

80 mm	LED	Indoor/Outdoor Use	Upright Mounting	Ambient Temperature -30°C~+60°C	Red, Amber, Green
Motorized Rotation	85dB	1 Alarm Sounds	IP23		



KES Type  
KESB Type (with buzzer)


### Model Number Configuration

## KESB-302-RYG

①      ②      ③      ④

① Buzzer None = None B = Buzzer	② Number of Tiers 1 = 1 Tier 2 = 2 Tiers 3 = 3 Tiers	③ Rated Voltage 02 = 24V DC 10 = 100V AC 20 = 220V AC	④ Color R = Red Y = Amber G = Green (Top to bottom)
---------------------------------------	---	--	---

### Dimensions (mm)

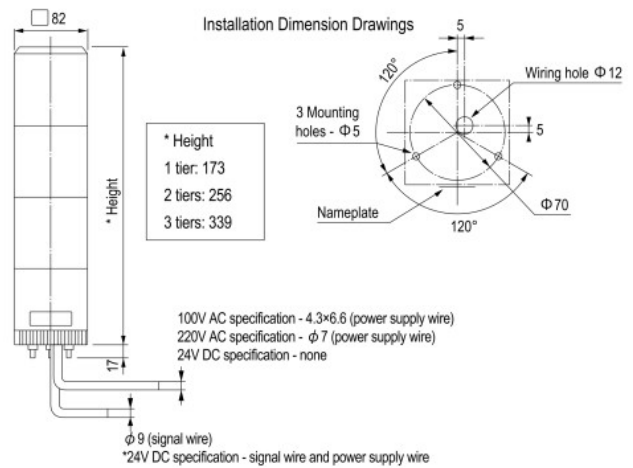

### Specification

Supported Transistors	NPN
Alarm Tone	Single tone (for KESB only)
Volume Control	Not adjustable

### Optional Parts

For details refer to P. 93 to P. 98

Product Name	Model Number
Wall Mount Bracket	SZ-007

### Product List

Model Number	Number of Tiers	Rated Voltage	Luminous Color	Power Consumption (KES)	Power Consumption (KESB)	Mass
KES(B)-102-R/Y/G	1	24V DC	Red / Amber / Green	5.5W	5.5W	0.4kg
KES(B)-110-R/Y/G	1	100V AC	Red / Amber / Green	6.4W	7.3W	0.8kg
KES(B)-120-R/Y/G	1	220V AC	Red / Amber / Green	6.4W	7.3W	0.8kg
KES(B)-202-RY/RG	2	24V DC	Red, Amber / Red, Green	10.5W	11.5W	1.0kg
KES(B)-210-RY/RG	2	100V AC	Red, Amber / Red, Green	10.5W	11.0W	1.4kg
KES(B)-220-RY/RG	2	220V AC	Red, Amber / Red, Green	10.5W	11.0W	1.4kg
KES(B)-302-RYG	3	24V DC	Red, Amber, Green	15.5W	16.5W	1.4kg
KES(B)-310-RYG	3	100V AC	Red, Amber, Green	14.0W	15.0W	1.8kg
KES(B)-320-RYG	3	220V AC	Red, Amber, Green	14.0W	15.0W	1.8kg