


T-Max® P insert for turning

Square

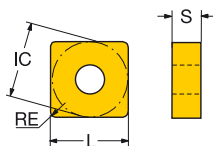


			P							M					K		S																
		ISO CODE	1515	1525	4205	4235	4315	4325	5015	GC30	1115	1125	2015	2025	2035	235	GC15	3205	3210	3215	GC30	HT3A	1105	1115	1125	GC15	HT3A	S05F	ANSI CODE				
D		09 3/8	SNMA 09 03 08-KR																☆	☆	☆								SNMA 322-KR				
		12 1/2	SNMA 12 04 08-KR																☆	☆	☆									SNMA 432-KR			
			SNMA 12 04 12-KR																	☆	☆	☆									SNMA 433-KR		
			SNMA 12 04 16-KR																		☆	☆	☆								SNMA 434-KR		
		15 5/8	SNMA 15 06 12-KR																	☆	☆	☆									SNMA 543-KR		
			SNMA 15 06 16-KR																		☆	☆	☆									SNMA 544-KR	
		19 3/4	SNMA 19 06 08-KR																	☆											SNMA 642-KR		
			SNMA 19 06 12-KR																	☆			☆									SNMA 643-KR	
			SNMA 19 06 16-KR																	☆	☆	☆										SNMA 644-KR	
	25 1	SNMA 25 07 24-KR																	☆	☆	☆										SNMA 856-KR		
	E		12 1/2	SNMG 12 04 08-KR															☆	☆	☆										SNMG 432-KR		
				SNMG 12 04 12-KR																☆	☆	☆										SNMG 433-KR	
				SNMG 12 04 16-KR																	☆	☆	☆										SNMG 434-KR
			15 5/8	SNMG 15 06 12-KR																☆	☆	☆										SNMG 543-KR	
				SNMG 15 06 16-KR																	☆	☆	☆										SNMG 544-KR
			19 3/4	SNMG 19 06 16-KR																	☆	☆	☆										SNMG 644-KR
	25 1	SNMG 25 07 24-KR																	☆	☆	☆										SNMG 856-KR		
	F		12 1/2	SNMM 12 04 08-QR				☆	☆										☆												SNMM 432-QR		
			SNMM 12 04 12-QR				☆	☆											☆												SNMM 433-QR		
			SNMM 12 04 16-QR				☆	☆																								SNMM 434-QR	
15 5/8			SNMM 15 06 08-QR				☆	☆																							SNMM 542-QR		
			SNMM 15 06 12-QR				☆	☆																								SNMM 543-QR	
			SNMM 15 06 16-QR				☆	☆																								SNMM 544-QR	
			SNMM 15 06 24-QR						☆	☆																						SNMM 546-QR	
19 3/4			SNMM 19 06 08-QR					☆	☆																						SNMM 642-QR		
			SNMM 19 06 12-QR					☆	☆	☆										☆												SNMM 643-QR	
		SNMM 19 06 16-QR					☆	☆	☆										☆													SNMM 644-QR	
		SNMM 19 06 24-QR							☆	☆									☆													SNMM 646-QR	
25 1		SNMM 25 07 24-QR							☆	☆																					SNMM 856-QR		
G			19 3/4	SNMM 19 06 16-HR				☆	☆	☆									☆												SNMM 644-HR		
				SNMM 19 06 24-HR				☆	☆	☆										☆												SNMM 646-HR	
			25 1	SNMM 25 07 24-HR					☆	☆	☆									☆												SNMM 856-HR	
				SNMM 25 07 32-HR					☆	☆	☆																						SNMM 858-HR
				SNMM 25 09 24-HR					☆	☆	☆										☆												SNMM 866-HR
				SNMM 25 09 32-HR					☆	☆	☆																						SNMM 868-HR
H		12 1/2	SNMG 12 04 08-MR											☆	☆	☆														SNMG 432-MR			
			SNMG 12 04 12-MR												☆	☆	☆														SNMG 433-MR		
		15 5/8	SNMG 15 06 12-MR																												SNMG 543-MR		
			SNMG 15 06 16-MR																													SNMG 544-MR	
		19 3/4	SNMG 19 06 12-MR																	☆	☆	☆									SNMG 642-MR		
	SNMG 19 06 16-MR																	☆	☆	☆										SNMG 644-MR			
	SNMG 19 06 24-MR																		☆	☆	☆									SNMG 646-MR			


For dimensions, see code key on page I14.



 A13



A27

 

A558



I1