


Plug Lead Type

Base Mounted

# Single Unit

## S0700 Series

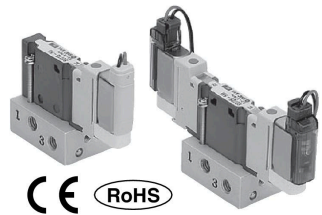

### How to Order Valves

S07 **1** **5**   - **5** **G** - **M5**

**Type of actuation**

Symbol	Specifications
<b>1</b>	2-position single
<b>2</b>	2-position double
<b>3</b>	3-position closed center
<b>A</b>	4-position dual 3-port (N.C. + N.C.) [Exhaust center]
<b>B</b>	4-position dual 3-port (N.O. + N.O.) [Pressure center]
<b>C</b>	4-position dual 3-port (N.C. + N.O.)

Note) For symbol, refer to page 741.

**Base Mounted**

**Function**

Symbol	Type
<b>Nil</b>	Standard
<b>R</b>	External pilot <small>Note)</small>

Note) Not compatible with dual 3-port valves.

**With/Without sub-plate**

Symbol	Type
<b>Nil</b>	Without sub-plate
<b>M5</b>	With sub-plate

**Electrical entry**

Symbol	Specifications	Configuration
<b>G</b>	Grommet	
<b>M</b>	M-type plug connector, with lead wire (With light/surge voltage suppressor)	
<b>MO</b>	M-type plug connector, without lead wire (With light/surge voltage suppressor)	

**Voltage**

Symbol	Type
<b>5</b>	24 VDC
<b>6</b>	12 VDC

SJ

SY

SY

S0700

S0700