



Dimensions





VHS4510/5510

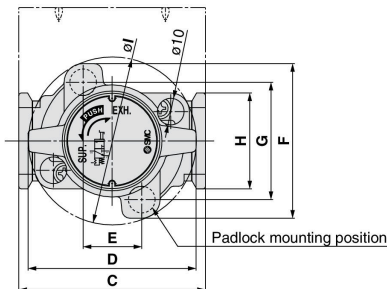

VHS3510

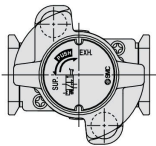

VHS2510

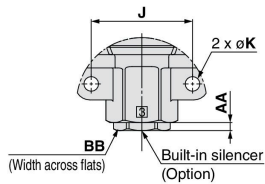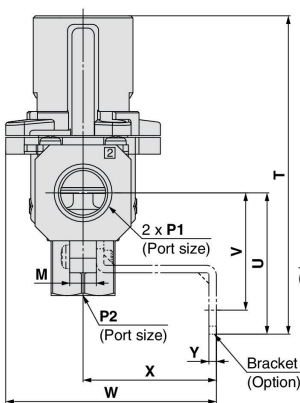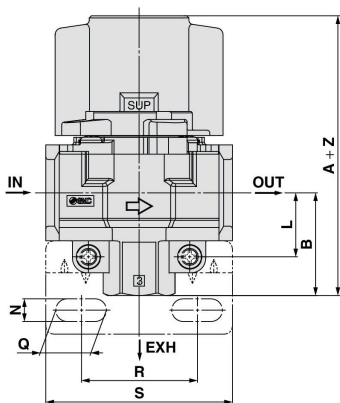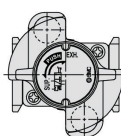

Dimensions

Model	Standard specifications																
	P1	P2	A	B	C	D	E	F		G	H	I	J	K	L	M	Z
								A type	B type								
VHS2510	1/8, 1/4	1/8	66.4	22.3	40	37.5	14	46.6	47.2	33.6	28	43	24	4.5	14.8	9	3.2
VHS3510	1/4, 3/8	1/4	80.3	29.4	53	49	19	52		38	30	49	30	4.5	19	9	3.2
VHS4510	1/4, 3/8, 1/2	3/8	104.9	38.5	70	63	22	58		44	36	63	38	5.5	24	10	4.2
VHS4510-06	3/4	1/2	110.4	42	75	63	22	58		44	44	63	43	5.5	26	10	4.2
VHS5510	3/4, 1	1/2	134.3	53	90	76	26	76		61	53	81	50	6.5	31	12	4.2

Model	Options specifications											Built-in silencer	
	With bracket												
	N	Q	R	S	T	U	V	W	X	Y	AA	BB	
VHS2510	5.4	8.4	27	40	75.4	31.3	25.3	53.3	30	2.3	3	12	
VHS3510	6.5	10	36.5	53	90.9	40	33	67	41	2.3	3	14	
VHS4510	8.5	19	43.5	70	119.4	53	44	79	50	2.8	3	19	
VHS4510-06	8.5	19	43.5	70	123.4	55	46	79	50	2.8	4	22	
VHS5510	11	27.5	49.5	90	152.3	71	60	108	70	3.2	4	22	

VM**VMG**

VR

VR51

VHK

VH

VHS

VHS