
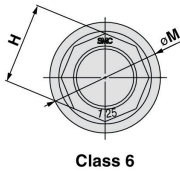


LQ1 Series

Dimensions

Union Tee: LQ1T

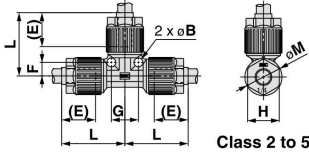

(E) shows the approximate dimension of the inserted tubing from the end of the nut.

Metric sizes

Model	Applicable tubing O.D.	B	E	F	G	H	L	M	Min. port size
LQ1T11	ø4	2	10	4	8	—	18.5	11.5	2.6
LQ1T12	ø3								1.8
LQ1T21□□	ø6	4	15	6	12	14	28	16.5	3.6
LQ1T22□□	ø4								2.6
LQ1T2C□□	ø3								1.8
LQ1T31□□	ø10								7.4
LQ1T32□□	ø8	5	20	9	18	17	36.5	23	5.5
LQ1T33□□	ø6								3.6
LQ1T41□□	ø12	6	24	9	18	21	43	28	9.4
LQ1T42□□	ø10								7.4
LQ1T51□□	ø19	7	29	14	28	26	54	39	15
LQ1T52□□	ø12								9.4
LQ1T61□□	ø25	8	39.5	18	36	36	69.5	49	21.2
LQ1T62□□	ø19								15

Inch sizes

Model	Applicable tubing O.D.	B	E	F	G	H	L	M	Min. port size
LQ1T1A	1/8"	2	10	4	8	—	18.5	11.5	1.8
LQ1T2A□□	1/4"								3.6
LQ1T2B□□	3/16"	4	15	6	12	14	28	16.5	2.9
LQ1T2C□□	1/8"								1.8
LQ1T3A□□	3/8"	5	20	9	18	17	36.5	23	5.8
LQ1T3B□□	1/4"								3.6
LQ1T4A□□	1/2"	6	24	9	18	21	43	28	9
LQ1T4B□□	3/8"								5.8
LQ1T5A□□	3/4"	7	29	14	28	26	54	39	15
LQ1T5B□□	1/2"								9
LQ1T6A□□	1"	8	39.5	18	36	36	69.5	49	21.2
LQ1T6B□□	3/4"								15