

# BN


- Tire Nylon 6
- Wheel center -
- Bearing -
- Operating temp. -40°C~+80°C
- Hardness (R) 100-110
- Characteristics Chemical, oil and wearing resistance.
- Applicable to Castors on P.47



BN-50	50	20	23	6	-	35 (340)
BN-65	65	25	30	8	-	50 (490)
BN-75	75	25	30	8	-	60 (580)

# CW

- Tire SBR
- Wheel center Steel SPHC-P
- Bearing **JBB** Radial ball bearing
- Operating temp. -30°C~+90°C
- Hardness (HS) 70-75
- Characteristics High elasticity.
- Applicable to Castors on P.13 P.55

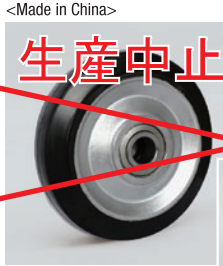

CW-100 <b>JBB</b>	100	35	42	12	15.0	130 (1270)
CW-130 <b>JBB</b>	130	42	52	20	17.0	180 (1760)
CW-150 <b>JBB</b>	150	45	55	20	17.0	200 (1960)
CW-200 <b>JBB</b>	200	45	55	20	17.0	250 (2450)



CW-200

# CYN

- Tire Nylon 6
- Wheel center -
- Bearing **JBB** Radial ball bearing
- Operating temp. -10°C~+60°C
- Hardness (R) 100-115
- Characteristics Oil resistance.
- Applicable to Castors on P.17



CYN-65 <b>JBB</b>	65	45	52	10	-	250 (2450)
CYN-75 <b>JBB</b>	75	46	52	10	-	320 (3130)

# CYN (for compact medium duty castors with stopper type)

- Tire Nylon 6
- Wheel center -
- Bearing **NB** Needle bearing
- Operating temp. -10°C~+60°C
- Hardness (R) 100-115
- Characteristics Oil resistance.
- Applicable to Castors on P.17



CYN-65S <b>NB</b>	65	45	46	10	-	250 (2450)
CYN-75S <b>NB</b>	75	46	46	10	-	320 (3130)

# EUW

ベアリング変更 JBB→CB

- Tire UR (Antistatic polyurethane)
- Wheel center Steel SPHC-P
- Bearing ~~JBB Radial ball bearing~~ → **CB**
- Operating temp. -30°C~+80°C
- Hardness (HS) 85-88
- Volume resistance 10<sup>6</sup>~10<sup>8</sup>Ω·cm\*
- Characteristics Antistatic. Shock and oil resistance. Floor saving.
- Applicable to Castors on P.25 P.35 P.51 P.53



EUW-75 <b>JBB</b>	75	32	35	10	10.0	120 (1170)
EUW-100 <b>JBB</b>	100	35	42	12	11.0	180 (1760)
EUW-130 <b>JBB</b>	130	42	52	20	13.5	250 (2450)
EUW-150 <b>JBB</b>	150	45	55	20	13.0	300 (2940)
EUW-200 <b>JBB</b>	200	45	55	20	14.0	400 (3920)

→CBIに変更

# LG (with Rubber tread)

- Tire Natural beech wood
- Wheel center -
- Bearing **OL** Oilless bushing
- Operating temp. -
- Hardness -
- Characteristics High quality natural beech wood. Natural color and different grain pattern.
- Applicable to Castors on P.59



LG-75 <b>OL</b>	75	26	29	6	-	30 (290)
-----------------	----	----	----	---	---	-------------

NB With steel bushing.