


Rotary Stage BRE Series □40□60: BRE04020/BRE06020

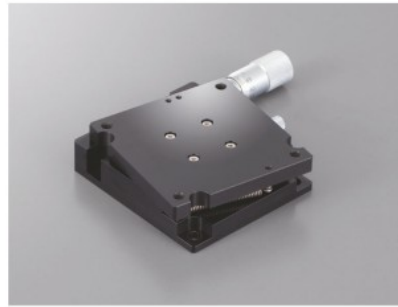

BRE04020



BRE06020

RoHS

Manual linear stage

X

XY

Z

Horizontal Z

XZ

Horizontal XZ

XYZ

Horizontal XYZ

Goniometer

Rotary

Unit

Accessories

Linear Ball

Cross Roller

Dovetail

□25

□30

□40

□50

□60

□70

□80

□100

□120

Other

1 Model
BRE04020
1 **2**

1 Stage table size

04	40mm
06	60mm

2 Travel distance

020	20°
-----	-----

SPEC		
Model	BRE04020	BRE06020
Stage table size	40×40mm	60×60mm
Travel distance	±10°	±10°
Minimum reading of micrometer	≒1'51"	≒1'12"
Travel guide	Fitting method	Fitting method
Load capacity	1kgf [9.8N]	3kgf [29.4N]
Parallelism	50μm	50μm
Weight	0.14kg	0.26kg
Main material—Surface finishing	Aluminum—Black alumite processing	Aluminum—Black alumite processing
Provided screws (Hex socket screws)	3 of M3—6	3 of M4—8