


Miter Rule 45° 90°



62081
32740
32674



62189

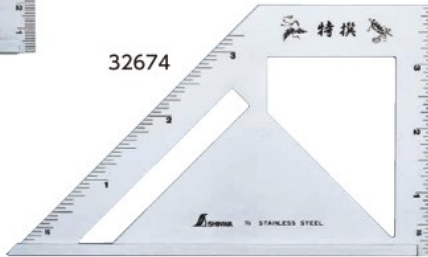


Item Code	Description	Body Size (mm)	Weight (g)	JAN Code	Packing Unit	Package
62081	Standard Model	170×100×15	177	4 960910 620810	6	
32740	Standard Model	170×100×15	177	4 960910 327405	6	
32674	Standard Model S-1462 Inch Graduations	170×100×15	177	4 960910 326743	6	
62189	with 40 mm Wide Fence	170×100×40	334	4 960910 621893	6	


Features

- Can be used to check 45° and 90° angles and marking work
- Mark both left and right 45° angles with one side

As Miter Gauge

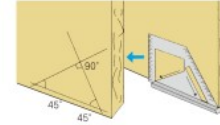

As Try Square

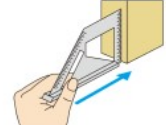


Use

- For matching 45° angles on framework
- For inspection of the right angle on material objects or products

Specifications

Item Code	62081	32740	32674	62189
Base Size (mm)	163 × 15 × 5 mm	163 × 15 × 5 mm	163 × 15 × 5 mm	163 × 40 × 5 mm
Thickness of Board	1.5 mm			
Angle Tolerance	45°: Less than 0.2 mm per 100 mm 90°: Less than 0.1 mm per 100 mm			
Length Tolerance	±0.3 mm			
Material	Stainless steel			

Miter Rule 45°

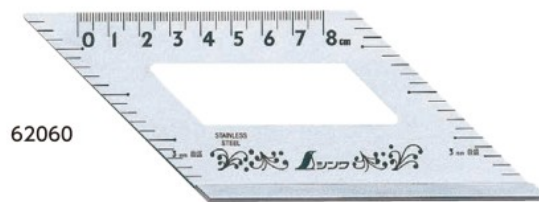

62103
32712
62060
62110



62162


Item Code	Description	Overall length×Width×Thickness (mm)	Weight (g)	JAN Code	Packing Unit	Package
62103	Standard Model	170×62×15	119	4 960910 621039	12	
32712	Standard Model	170×62×15	119	4 960910 327122	12	
62060	with Graduations	170×62×15	119	4 960910 620605	12	
62110	with Right Angle	170×62×15	133	4 960910 621107	12	
62162	with 40 mm Wide Fence	170×62×40	251	4 960910 621626	6	

Features

- Helps check and scribe 45° easily
- Top has a cm scale and edges have 3 mm (equivalent to 1/100th of a shaku) pitch graduations (62060)
- Top and edge have 3 mm (equivalent to 1/100th of a shaku) pitch graduations (62110)
- Can confirm 45° and 90° angles at the same time, and is easy to use for scribing
- Four different types available: Standard, with Graduations, with Right Angle, and with 40 mm Wide Fence

Use

- For confirming 45° angles, drawing lines, and scribing
- With Right Angle: Checking 90° angles, drawing lines, and scribing (62110)

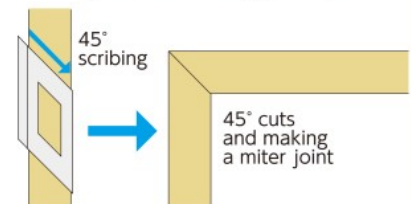

Specifications

Item Code	62103	32712	62060	62110	62162
Base Size	115×15×5mm	115×15×5mm	115×15×5mm	115×15×5mm	116×40×6mm
Thickness of Board	1.5mm				1.3mm
Angle Tolerance	Less than 0.2 mm per 100 mm				
Length Tolerance	±0.3 mm				
Material	Stainless steel				