



**A-224**  
アルミニウム製

特 徴 Feature

- アルミ芯材に塩化ビニルを巻き付けたソフトな取手です。
- 抗菌材配合により細菌類、カビ類などの繁殖および悪臭を防ぎます。
- 半永久的に抗菌効果を持続します。
- 止め金具・通し金具を用意しています。
- Chloride resin around the aluminum core makes the soft touch handle.
- Prevent for getting moldy and bacterial and shut out unpleasant smell.
- Keep antibacterial effects for almost semipermanent periods.
- The stopper and the through fitting are provided.

- 仕 様 ●材 質  
丸棒／アルミニウム押出し材・塩化ビニル押出し材  
金具／アルミニウム合金(ADC)
- 表面仕上: 焼付塗装(シルバーメタリック)
  - 標準色: グレー(パイプ)
- 用 途 ●バス内装取手・鉄道車両
- 納 期 ●標準在庫品
- 備 考 ●任意の長さで製作致します。(4mまで)

- Specifi- ●Material: Round rod: Aluminum extruded material・  
cations Polyvinyl chloride resin extruded material.  
Fitting: Aluminum alloy (ADC)
- Finish: Backed (silver metallic)
  - Standard color: Gray (round rod section)
- Specific- ●Pulls installed on the inside of buses  
use and trains.

**ソフト抗菌取手**  
SOFT-IMAGE ANTIBACTERIAL PULLS

PAT.PEND.




A-224-P

A-224-B






A-224-A

[A-224-P] 塩化ビニル押出しパイプ  
Polyvinyl chloride resin extruded pipe

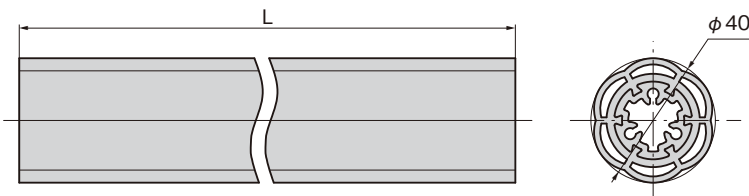

[A-224-A] 止め金具  
Stopper

[A-224-B] 通し金具  
Through fitting

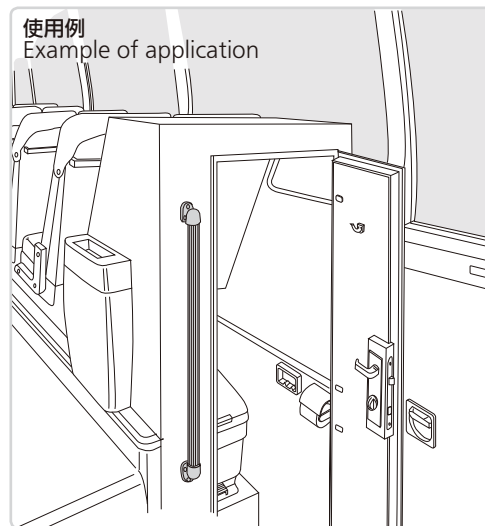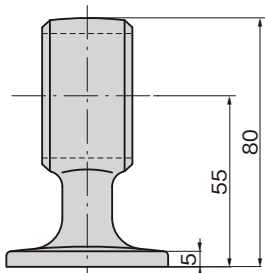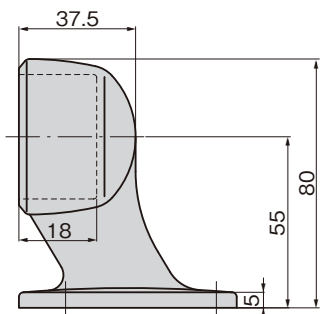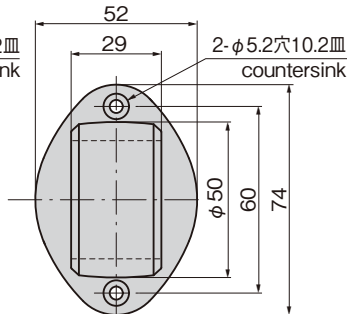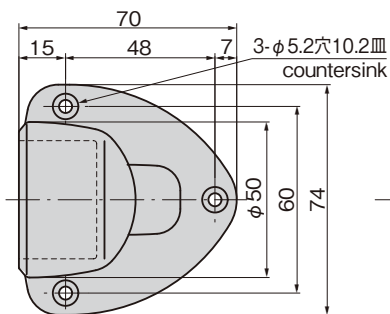

商品番号 Product No.	RoHS	CAD	備考 Remarks	L	製品質量(g) Mass	コード Code	単価 Price	量販価格 数量 Quantity	Bulk Price 単価 Price
A-224-P-1000		2D		1000	1,350	01764	¥3,400	5個～	¥3,264
A-224-P-500		2D	パイプ Pipe	500	680	01763	¥1,820	10個～	¥1,747
A-224-P-300		2D		300	410	01762	¥1,240	10個～	¥1,190
A-224-A		2D	止め金具 Fitting		70	01687	¥800	20個～	¥768
A-224-B		2D	通し金具 Through fitting		60	01688	¥1,000	30個～	¥960

●: RoHS指令対応品 ▲: RoHS指令に対応可能です。※大量のご注文は更にお安くなります。

ハンドル・取手  
つまみ・周辺機器



A

クレモン

ローラー  
締り

特装密閉  
ハンドル

フリーザー  
密閉

平面  
スイング

ギア式

平面  
ハンドル

ポップ  
ハンドル

リフト  
ハンドル

アジャスト  
ハンドル

ラッチ式

スナッチ

リンク

フック式

ロック  
ハンドル

L 型  
ハンドル

T 型  
ハンドル

丸型  
小型

押ボタン

PULLS 取手

つまみ

止め金  
ロッド棒

ジョイント  
リンク

ワイヤ